


Item description/product images

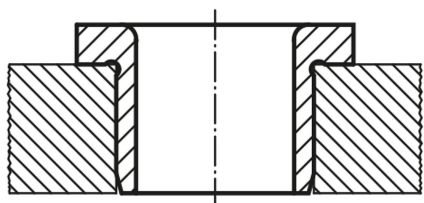

Description

Material:
Special low carbon steel


Version:
Hardened to 740 ±80 HV 10 and ground.

Note:
From diameter D1 over 15 mm size increases are 0.5 mm.

Drawing reference:
Form A: hole rounded one end
Form B: hole rounded both ends

1) Chamfer for insert

Drawings

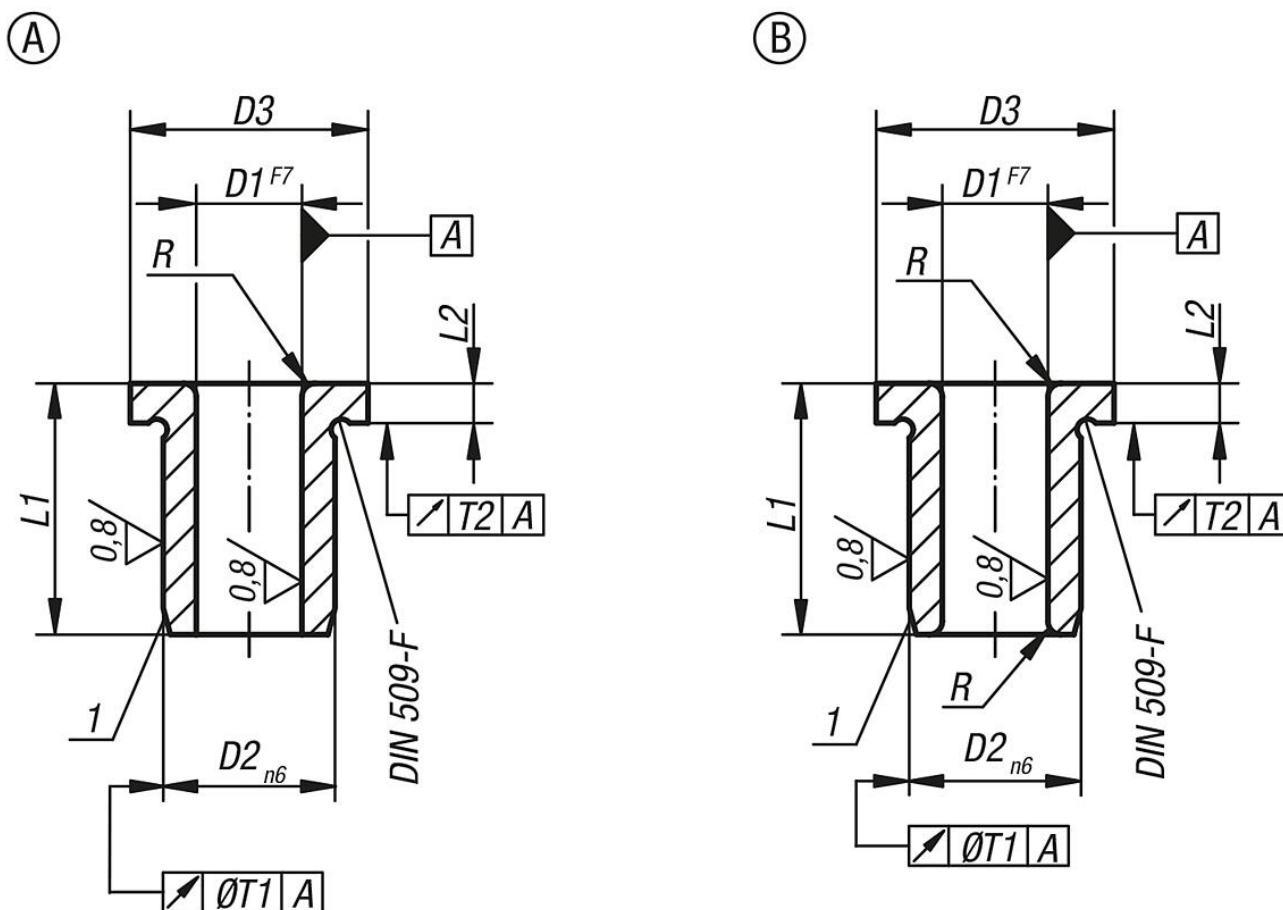

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A0040X06	A	0,4	3	6	6	short	2	1	0,01	0,03
08910-A0050X06	A	0,5	3	6	6	short	2	1	0,01	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A0060X06	A	0,6	3	6	6	short	2	1	0,01	0,03
08910-A0070X06	A	0,7	3	6	6	short	2	1	0,01	0,03
08910-A0080X06	A	0,8	3	6	6	short	2	1	0,01	0,03
08910-A0090X06	A	0,9	3	6	6	short	2	1	0,01	0,03
08910-A0090X09	A	0,9	3	6	9	medium	2	1	0,01	0,03
08910-A0100X06	A	1	3	6	6	short	2	1	0,01	0,03
08910-A0100X09	A	1	3	6	9	medium	2	1	0,01	0,03
08910-A0110X06	A	1,1	4	7	6	short	2	1	0,01	0,03
08910-A0110X09	A	1,1	4	7	9	medium	2	1	0,01	0,03
08910-A0120X06	A	1,2	4	7	6	short	2	1	0,01	0,03
08910-A0120X09	A	1,2	4	7	9	medium	2	1	0,01	0,03
08910-A0130X06	A	1,3	4	7	6	short	2	1	0,01	0,03
08910-A0130X09	A	1,3	4	7	9	medium	2	1	0,01	0,03
08910-A0140X06	A	1,4	4	7	6	short	2	1	0,01	0,03
08910-A0140X09	A	1,4	4	7	9	medium	2	1	0,01	0,03
08910-A0150X06	A	1,5	4	7	6	short	2	1	0,01	0,03
08910-A0150X09	A	1,5	4	7	9	medium	2	1	0,01	0,03
08910-A0160X06	A	1,6	4	7	6	short	2	1	0,01	0,03
08910-A0160X09	A	1,6	4	7	9	medium	2	1	0,01	0,03
08910-A0170X06	A	1,7	4	7	6	short	2	1	0,01	0,03
08910-A0170X09	A	1,7	4	7	9	medium	2	1	0,01	0,03
08910-A0180X06	A	1,8	4	7	6	short	2	1	0,01	0,03
08910-A0180X09	A	1,8	4	7	9	medium	2	1	0,01	0,03
08910-A0190X06	A	1,9	5	8	6	short	2	1	0,01	0,03
08910-A0190X09	A	1,9	5	8	9	medium	2	1	0,01	0,03
08910-A0200X06	A	2	5	8	6	short	2	1	0,01	0,03
08910-A0200X09	A	2	5	8	9	medium	2	1	0,01	0,03
08910-A0210X06	A	2,1	5	8	6	short	2	1	0,01	0,03
08910-A0210X09	A	2,1	5	8	9	medium	2	1	0,01	0,03
08910-A0220X06	A	2,2	5	8	6	short	2	1	0,01	0,03
08910-A0220X09	A	2,2	5	8	9	medium	2	1	0,01	0,03
08910-A0230X06	A	2,3	5	8	6	short	2	1	0,01	0,03
08910-A0230X09	A	2,3	5	8	9	medium	2	1	0,01	0,03
08910-A0240X06	A	2,4	5	8	6	short	2	1	0,01	0,03
08910-A0240X09	A	2,4	5	8	9	medium	2	1	0,01	0,03
08910-A0250X06	A	2,5	5	8	6	short	2	1	0,01	0,03
08910-A0250X09	A	2,5	5	8	9	medium	2	1	0,01	0,03
08910-A0260X06	A	2,6	5	8	6	short	2	1	0,01	0,03
08910-A0260X09	A	2,6	5	8	9	medium	2	1	0,01	0,03
08910-A0270X08	A	2,7	6	9	8	short	2,5	1	0,01	0,03
08910-A0270X12	A	2,7	6	9	12	medium	2,5	1	0,01	0,03
08910-A0270X16	A	2,7	6	9	16	long	2,5	1	0,01	0,03
08910-A0280X08	A	2,8	6	9	8	short	2,5	1	0,01	0,03
08910-A0280X12	A	2,8	6	9	12	medium	2,5	1	0,01	0,03
08910-A0280X16	A	2,8	6	9	16	long	2,5	1	0,01	0,03
08910-A0290X08	A	2,9	6	9	8	short	2,5	1	0,01	0,03
08910-A0290X12	A	2,9	6	9	12	medium	2,5	1	0,01	0,03
08910-A0290X16	A	2,9	6	9	16	long	2,5	1	0,01	0,03
08910-A0300X08	A	3	6	9	8	short	2,5	1	0,01	0,03
08910-A0300X12	A	3	6	9	12	medium	2,5	1	0,01	0,03
08910-A0300X16	A	3	6	9	16	long	2,5	1	0,01	0,03
08910-A0310X08	A	3,1	6	9	8	short	2,5	1	0,01	0,03
08910-A0310X12	A	3,1	6	9	12	medium	2,5	1	0,01	0,03
08910-A0310X16	A	3,1	6	9	16	long	2,5	1	0,01	0,03
08910-A0320X08	A	3,2	6	9	8	short	2,5	1	0,01	0,03
08910-A0320X12	A	3,2	6	9	12	medium	2,5	1	0,01	0,03
08910-A0320X16	A	3,2	6	9	16	long	2,5	1	0,01	0,03
08910-A0330X08	A	3,3	6	9	8	short	2,5	1	0,01	0,03
08910-A0330X12	A	3,3	6	9	12	medium	2,5	1	0,01	0,03
08910-A0330X16	A	3,3	6	9	16	long	2,5	1	0,01	0,03
08910-A0340X08	A	3,4	7	10	8	short	2,5	1	0,01	0,03
08910-A0340X12	A	3,4	7	10	12	medium	2,5	1	0,01	0,03
08910-A0340X16	A	3,4	7	10	16	long	2,5	1	0,01	0,03
08910-A0350X08	A	3,5	7	10	8	short	2,5	1	0,01	0,03
08910-A0350X12	A	3,5	7	10	12	medium	2,5	1	0,01	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A0350X16	A	3,5	7	10	16	long	2,5	1	0,01	0,03
08910-A0360X08	A	3,6	7	10	8	short	2,5	1	0,01	0,03
08910-A0360X12	A	3,6	7	10	12	medium	2,5	1	0,01	0,03
08910-A0360X16	A	3,6	7	10	16	long	2,5	1	0,01	0,03
08910-A0370X08	A	3,7	7	10	8	short	2,5	1	0,01	0,03
08910-A0370X12	A	3,7	7	10	12	medium	2,5	1	0,01	0,03
08910-A0370X16	A	3,7	7	10	16	long	2,5	1	0,01	0,03
08910-A0380X08	A	3,8	7	10	8	short	2,5	1	0,01	0,03
08910-A0380X12	A	3,8	7	10	12	medium	2,5	1	0,01	0,03
08910-A0380X16	A	3,8	7	10	16	long	2,5	1	0,01	0,03
08910-A0390X08	A	3,9	7	10	8	short	2,5	1	0,01	0,03
08910-A0390X12	A	3,9	7	10	12	medium	2,5	1	0,01	0,03
08910-A0390X16	A	3,9	7	10	16	long	2,5	1	0,01	0,03
08910-A0400X08	A	4	7	10	8	short	2,5	1	0,01	0,03
08910-A0400X12	A	4	7	10	12	medium	2,5	1	0,01	0,03
08910-A0400X16	A	4	7	10	16	long	2,5	1	0,01	0,03
08910-A0410X08	A	4,1	8	11	8	short	2,5	1	0,01	0,03
08910-A0410X12	A	4,1	8	11	12	medium	2,5	1	0,01	0,03
08910-A0410X16	A	4,1	8	11	16	long	2,5	1	0,01	0,03
08910-A0420X08	A	4,2	8	11	8	short	2,5	1	0,01	0,03
08910-A0420X12	A	4,2	8	11	12	medium	2,5	1	0,01	0,03
08910-A0420X16	A	4,2	8	11	16	long	2,5	1	0,01	0,03
08910-A0430X08	A	4,3	8	11	8	short	2,5	1	0,01	0,03
08910-A0430X12	A	4,3	8	11	12	medium	2,5	1	0,01	0,03
08910-A0430X16	A	4,3	8	11	16	long	2,5	1	0,01	0,03
08910-A0440X08	A	4,4	8	11	8	short	2,5	1	0,01	0,03
08910-A0440X12	A	4,4	8	11	12	medium	2,5	1	0,01	0,03
08910-A0440X16	A	4,4	8	11	16	long	2,5	1	0,01	0,03
08910-A0450X08	A	4,5	8	11	8	short	2,5	1	0,01	0,03
08910-A0450X12	A	4,5	8	11	12	medium	2,5	1	0,01	0,03
08910-A0450X16	A	4,5	8	11	16	long	2,5	1	0,01	0,03
08910-A0460X08	A	4,6	8	11	8	short	2,5	1	0,01	0,03
08910-A0460X12	A	4,6	8	11	12	medium	2,5	1	0,01	0,03
08910-A0460X16	A	4,6	8	11	16	long	2,5	1	0,01	0,03
08910-A0470X08	A	4,7	8	11	8	short	2,5	1	0,01	0,03
08910-A0470X12	A	4,7	8	11	12	medium	2,5	1	0,01	0,03
08910-A0470X16	A	4,7	8	11	16	long	2,5	1	0,01	0,03
08910-A0480X08	A	4,8	8	11	8	short	2,5	1	0,01	0,03
08910-A0480X12	A	4,8	8	11	12	medium	2,5	1	0,01	0,03
08910-A0480X16	A	4,8	8	11	16	long	2,5	1	0,01	0,03
08910-A0490X08	A	4,9	8	11	8	short	2,5	1	0,01	0,03
08910-A0490X12	A	4,9	8	11	12	medium	2,5	1	0,01	0,03
08910-A0490X16	A	4,9	8	11	16	long	2,5	1	0,01	0,03
08910-A0500X08	A	5	8	11	8	short	2,5	1	0,01	0,03
08910-A0500X12	A	5	8	11	12	medium	2,5	1	0,01	0,03
08910-A0500X16	A	5	8	11	16	long	2,5	1	0,01	0,03
08910-A0510X10	A	5,1	10	13	10	short	3	1,5	0,02	0,03
08910-A0510X16	A	5,1	10	13	16	medium	3	1,5	0,02	0,03
08910-A0510X20	A	5,1	10	13	20	long	3	1,5	0,02	0,03
08910-A0520X10	A	5,2	10	13	10	short	3	1,5	0,02	0,03
08910-A0520X16	A	5,2	10	13	16	medium	3	1,5	0,02	0,03
08910-A0520X20	A	5,2	10	13	20	long	3	1,5	0,02	0,03
08910-A0530X10	A	5,3	10	13	10	short	3	1,5	0,02	0,03
08910-A0530X16	A	5,3	10	13	16	medium	3	1,5	0,02	0,03
08910-A0530X20	A	5,3	10	13	20	long	3	1,5	0,02	0,03
08910-A0540X10	A	5,4	10	13	10	short	3	1,5	0,02	0,03
08910-A0540X16	A	5,4	10	13	16	medium	3	1,5	0,02	0,03
08910-A0540X20	A	5,4	10	13	20	long	3	1,5	0,02	0,03
08910-A0550X10	A	5,5	10	13	10	short	3	1,5	0,02	0,03
08910-A0550X16	A	5,5	10	13	16	medium	3	1,5	0,02	0,03
08910-A0550X20	A	5,5	10	13	20	long	3	1,5	0,02	0,03
08910-A0560X10	A	5,6	10	13	10	short	3	1,5	0,02	0,03
08910-A0560X16	A	5,6	10	13	16	medium	3	1,5	0,02	0,03
08910-A0560X20	A	5,6	10	13	20	long	3	1,5	0,02	0,03
08910-A0570X10	A	5,7	10	13	10	short	3	1,5	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A0570X16	A	5,7	10	13	16	medium	3	1,5	0,02	0,03
08910-A0570X20	A	5,7	10	13	20	long	3	1,5	0,02	0,03
08910-A0580X10	A	5,8	10	13	10	short	3	1,5	0,02	0,03
08910-A0580X16	A	5,8	10	13	16	medium	3	1,5	0,02	0,03
08910-A0580X20	A	5,8	10	13	20	long	3	1,5	0,02	0,03
08910-A0590X10	A	5,9	10	13	10	short	3	1,5	0,02	0,03
08910-A0590X16	A	5,9	10	13	16	medium	3	1,5	0,02	0,03
08910-A0590X20	A	5,9	10	13	20	long	3	1,5	0,02	0,03
08910-A0600X10	A	6	10	13	10	short	3	1,5	0,02	0,03
08910-A0600X16	A	6	10	13	16	medium	3	1,5	0,02	0,03
08910-A0600X20	A	6	10	13	20	long	3	1,5	0,02	0,03
08910-A0610X10	A	6,1	12	15	10	short	3	1,5	0,02	0,03
08910-A0610X16	A	6,1	12	15	16	medium	3	1,5	0,02	0,03
08910-A0610X20	A	6,1	12	15	20	long	3	1,5	0,02	0,03
08910-A0620X10	A	6,2	12	15	10	short	3	1,5	0,02	0,03
08910-A0620X16	A	6,2	12	15	16	medium	3	1,5	0,02	0,03
08910-A0620X20	A	6,2	12	15	20	long	3	1,5	0,02	0,03
08910-A0630X10	A	6,3	12	15	10	short	3	1,5	0,02	0,03
08910-A0630X16	A	6,3	12	15	16	medium	3	1,5	0,02	0,03
08910-A0630X20	A	6,3	12	15	20	long	3	1,5	0,02	0,03
08910-A0640X10	A	6,4	12	15	10	short	3	1,5	0,02	0,03
08910-A0640X16	A	6,4	12	15	16	medium	3	1,5	0,02	0,03
08910-A0640X20	A	6,4	12	15	20	long	3	1,5	0,02	0,03
08910-A0650X10	A	6,5	12	15	10	short	3	1,5	0,02	0,03
08910-A0650X16	A	6,5	12	15	16	medium	3	1,5	0,02	0,03
08910-A0650X20	A	6,5	12	15	20	long	3	1,5	0,02	0,03
08910-A0660X10	A	6,6	12	15	10	short	3	1,5	0,02	0,03
08910-A0660X16	A	6,6	12	15	16	medium	3	1,5	0,02	0,03
08910-A0660X20	A	6,6	12	15	20	long	3	1,5	0,02	0,03
08910-A0670X10	A	6,7	12	15	10	short	3	1,5	0,02	0,03
08910-A0670X16	A	6,7	12	15	16	medium	3	1,5	0,02	0,03
08910-A0670X20	A	6,7	12	15	20	long	3	1,5	0,02	0,03
08910-A0680X10	A	6,8	12	15	10	short	3	1,5	0,02	0,03
08910-A0680X16	A	6,8	12	15	16	medium	3	1,5	0,02	0,03
08910-A0680X20	A	6,8	12	15	20	long	3	1,5	0,02	0,03
08910-A0690X10	A	6,9	12	15	10	short	3	1,5	0,02	0,03
08910-A0690X16	A	6,9	12	15	16	medium	3	1,5	0,02	0,03
08910-A0690X20	A	6,9	12	15	20	long	3	1,5	0,02	0,03
08910-A0700X10	A	7	12	15	10	short	3	1,5	0,02	0,03
08910-A0700X16	A	7	12	15	16	medium	3	1,5	0,02	0,03
08910-A0700X20	A	7	12	15	20	long	3	1,5	0,02	0,03
08910-A0710X10	A	7,1	12	15	10	short	3	1,5	0,02	0,03
08910-A0710X16	A	7,1	12	15	16	medium	3	1,5	0,02	0,03
08910-A0710X20	A	7,1	12	15	20	long	3	1,5	0,02	0,03
08910-A0720X10	A	7,2	12	15	10	short	3	1,5	0,02	0,03
08910-A0720X16	A	7,2	12	15	16	medium	3	1,5	0,02	0,03
08910-A0720X20	A	7,2	12	15	20	long	3	1,5	0,02	0,03
08910-A0730X10	A	7,3	12	15	10	short	3	1,5	0,02	0,03
08910-A0730X16	A	7,3	12	15	16	medium	3	1,5	0,02	0,03
08910-A0730X20	A	7,3	12	15	20	long	3	1,5	0,02	0,03
08910-A0740X10	A	7,4	12	15	10	short	3	1,5	0,02	0,03
08910-A0740X16	A	7,4	12	15	16	medium	3	1,5	0,02	0,03
08910-A0740X20	A	7,4	12	15	20	long	3	1,5	0,02	0,03
08910-A0750X10	A	7,5	12	15	10	short	3	1,5	0,02	0,03
08910-A0750X16	A	7,5	12	15	16	medium	3	1,5	0,02	0,03
08910-A0750X20	A	7,5	12	15	20	long	3	1,5	0,02	0,03
08910-A0760X10	A	7,6	12	15	10	short	3	1,5	0,02	0,03
08910-A0760X16	A	7,6	12	15	16	medium	3	1,5	0,02	0,03
08910-A0760X20	A	7,6	12	15	20	long	3	1,5	0,02	0,03
08910-A0770X10	A	7,7	12	15	10	short	3	1,5	0,02	0,03
08910-A0770X16	A	7,7	12	15	16	medium	3	1,5	0,02	0,03
08910-A0770X20	A	7,7	12	15	20	long	3	1,5	0,02	0,03
08910-A0780X10	A	7,8	12	15	10	short	3	1,5	0,02	0,03
08910-A0780X16	A	7,8	12	15	16	medium	3	1,5	0,02	0,03
08910-A0780X20	A	7,8	12	15	20	long	3	1,5	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A0790X10	A	7,9	12	15	10	short	3	1,5	0,02	0,03
08910-A0790X16	A	7,9	12	15	16	medium	3	1,5	0,02	0,03
08910-A0790X20	A	7,9	12	15	20	long	3	1,5	0,02	0,03
08910-A0800X10	A	8	12	15	10	short	3	1,5	0,02	0,03
08910-A0800X16	A	8	12	15	16	medium	3	1,5	0,02	0,03
08910-A0800X20	A	8	12	15	20	long	3	1,5	0,02	0,03
08910-A0810X12	A	8,1	15	18	12	short	3	2	0,02	0,03
08910-A0810X20	A	8,1	15	18	20	medium	3	2	0,02	0,03
08910-A0810X25	A	8,1	15	18	25	long	3	2	0,02	0,03
08910-A0820X12	A	8,2	15	18	12	short	3	2	0,02	0,03
08910-A0820X20	A	8,2	15	18	20	medium	3	2	0,02	0,03
08910-A0820X25	A	8,2	15	18	25	long	3	2	0,02	0,03
08910-A0830X12	A	8,3	15	18	12	short	3	2	0,02	0,03
08910-A0830X20	A	8,3	15	18	20	medium	3	2	0,02	0,03
08910-A0830X25	A	8,3	15	18	25	long	3	2	0,02	0,03
08910-A0840X12	A	8,4	15	18	12	short	3	2	0,02	0,03
08910-A0840X20	A	8,4	15	18	20	medium	3	2	0,02	0,03
08910-A0840X25	A	8,4	15	18	25	long	3	2	0,02	0,03
08910-A0850X12	A	8,5	15	18	12	short	3	2	0,02	0,03
08910-A0850X20	A	8,5	15	18	20	medium	3	2	0,02	0,03
08910-A0850X25	A	8,5	15	18	25	long	3	2	0,02	0,03
08910-A0860X12	A	8,6	15	18	12	short	3	2	0,02	0,03
08910-A0860X20	A	8,6	15	18	20	medium	3	2	0,02	0,03
08910-A0860X25	A	8,6	15	18	25	long	3	2	0,02	0,03
08910-A0870X12	A	8,7	15	18	12	short	3	2	0,02	0,03
08910-A0870X20	A	8,7	15	18	20	medium	3	2	0,02	0,03
08910-A0870X25	A	8,7	15	18	25	long	3	2	0,02	0,03
08910-A0880X12	A	8,8	15	18	12	short	3	2	0,02	0,03
08910-A0880X20	A	8,8	15	18	20	medium	3	2	0,02	0,03
08910-A0880X25	A	8,8	15	18	25	long	3	2	0,02	0,03
08910-A0890X12	A	8,9	15	18	12	short	3	2	0,02	0,03
08910-A0890X20	A	8,9	15	18	20	medium	3	2	0,02	0,03
08910-A0890X25	A	8,9	15	18	25	long	3	2	0,02	0,03
08910-A0900X12	A	9	15	18	12	short	3	2	0,02	0,03
08910-A0900X20	A	9	15	18	20	medium	3	2	0,02	0,03
08910-A0900X25	A	9	15	18	25	long	3	2	0,02	0,03
08910-A0910X12	A	9,1	15	18	12	short	3	2	0,02	0,03
08910-A0910X20	A	9,1	15	18	20	medium	3	2	0,02	0,03
08910-A0910X25	A	9,1	15	18	25	long	3	2	0,02	0,03
08910-A0920X12	A	9,2	15	18	12	short	3	2	0,02	0,03
08910-A0920X20	A	9,2	15	18	20	medium	3	2	0,02	0,03
08910-A0920X25	A	9,2	15	18	25	long	3	2	0,02	0,03
08910-A0930X12	A	9,3	15	18	12	short	3	2	0,02	0,03
08910-A0930X20	A	9,3	15	18	20	medium	3	2	0,02	0,03
08910-A0930X25	A	9,3	15	18	25	long	3	2	0,02	0,03
08910-A0940X12	A	9,4	15	18	12	short	3	2	0,02	0,03
08910-A0940X20	A	9,4	15	18	20	medium	3	2	0,02	0,03
08910-A0940X25	A	9,4	15	18	25	long	3	2	0,02	0,03
08910-A0950X12	A	9,5	15	18	12	short	3	2	0,02	0,03
08910-A0950X20	A	9,5	15	18	20	medium	3	2	0,02	0,03
08910-A0950X25	A	9,5	15	18	25	long	3	2	0,02	0,03
08910-A0960X12	A	9,6	15	18	12	short	3	2	0,02	0,03
08910-A0960X20	A	9,6	15	18	20	medium	3	2	0,02	0,03
08910-A0960X25	A	9,6	15	18	25	long	3	2	0,02	0,03
08910-A0970X12	A	9,7	15	18	12	short	3	2	0,02	0,03
08910-A0970X20	A	9,7	15	18	20	medium	3	2	0,02	0,03
08910-A0970X25	A	9,7	15	18	25	long	3	2	0,02	0,03
08910-A0980X12	A	9,8	15	18	12	short	3	2	0,02	0,03
08910-A0980X20	A	9,8	15	18	20	medium	3	2	0,02	0,03
08910-A0980X25	A	9,8	15	18	25	long	3	2	0,02	0,03
08910-A0990X12	A	9,9	15	18	12	short	3	2	0,02	0,03
08910-A0990X20	A	9,9	15	18	20	medium	3	2	0,02	0,03
08910-A0990X25	A	9,9	15	18	25	long	3	2	0,02	0,03
08910-A1000X12	A	10	15	18	12	short	3	2	0,02	0,03
08910-A1000X20	A	10	15	18	20	medium	3	2	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A1000X25	A	10	15	18	25	long	3	2	0,02	0,03
08910-A1010X12	A	10,1	18	22	12	short	4	2	0,02	0,03
08910-A1010X20	A	10,1	18	22	20	medium	4	2	0,02	0,03
08910-A1010X25	A	10,1	18	22	25	long	4	2	0,02	0,03
08910-A1020X12	A	10,2	18	22	12	short	4	2	0,02	0,03
08910-A1020X20	A	10,2	18	22	20	medium	4	2	0,02	0,03
08910-A1020X25	A	10,2	18	22	25	long	4	2	0,02	0,03
08910-A1030X12	A	10,3	18	22	12	short	4	2	0,02	0,03
08910-A1030X20	A	10,3	18	22	20	medium	4	2	0,02	0,03
08910-A1030X25	A	10,3	18	22	25	long	4	2	0,02	0,03
08910-A1040X12	A	10,4	18	22	12	short	4	2	0,02	0,03
08910-A1040X20	A	10,4	18	22	20	medium	4	2	0,02	0,03
08910-A1040X25	A	10,4	18	22	25	long	4	2	0,02	0,03
08910-A1050X12	A	10,5	18	22	12	short	4	2	0,02	0,03
08910-A1050X20	A	10,5	18	22	20	medium	4	2	0,02	0,03
08910-A1050X25	A	10,5	18	22	25	long	4	2	0,02	0,03
08910-A1060X12	A	10,6	18	22	12	short	4	2	0,02	0,03
08910-A1060X20	A	10,6	18	22	20	medium	4	2	0,02	0,03
08910-A1060X25	A	10,6	18	22	25	long	4	2	0,02	0,03
08910-A1070X12	A	10,7	18	22	12	short	4	2	0,02	0,03
08910-A1070X20	A	10,7	18	22	20	medium	4	2	0,02	0,03
08910-A1070X25	A	10,7	18	22	25	long	4	2	0,02	0,03
08910-A1080X12	A	10,8	18	22	12	short	4	2	0,02	0,03
08910-A1080X20	A	10,8	18	22	20	medium	4	2	0,02	0,03
08910-A1080X25	A	10,8	18	22	25	long	4	2	0,02	0,03
08910-A1090X12	A	10,9	18	22	12	short	4	2	0,02	0,03
08910-A1090X20	A	10,9	18	22	20	medium	4	2	0,02	0,03
08910-A1090X25	A	10,9	18	22	25	long	4	2	0,02	0,03
08910-A1100X12	A	11	18	22	12	short	4	2	0,02	0,03
08910-A1100X20	A	11	18	22	20	medium	4	2	0,02	0,03
08910-A1100X25	A	11	18	22	25	long	4	2	0,02	0,03
08910-A1110X12	A	11,1	18	22	12	short	4	2	0,02	0,03
08910-A1110X20	A	11,1	18	22	20	medium	4	2	0,02	0,03
08910-A1110X25	A	11,1	18	22	25	long	4	2	0,02	0,03
08910-A1120X12	A	11,2	18	22	12	short	4	2	0,02	0,03
08910-A1120X20	A	11,2	18	22	20	medium	4	2	0,02	0,03
08910-A1120X25	A	11,2	18	22	25	long	4	2	0,02	0,03
08910-A1130X12	A	11,3	18	22	12	short	4	2	0,02	0,03
08910-A1130X20	A	11,3	18	22	20	medium	4	2	0,02	0,03
08910-A1130X25	A	11,3	18	22	25	long	4	2	0,02	0,03
08910-A1140X12	A	11,4	18	22	12	short	4	2	0,02	0,03
08910-A1140X20	A	11,4	18	22	20	medium	4	2	0,02	0,03
08910-A1140X25	A	11,4	18	22	25	long	4	2	0,02	0,03
08910-A1150X12	A	11,5	18	22	12	short	4	2	0,02	0,03
08910-A1150X20	A	11,5	18	22	20	medium	4	2	0,02	0,03
08910-A1150X25	A	11,5	18	22	25	long	4	2	0,02	0,03
08910-A1160X12	A	11,6	18	22	12	short	4	2	0,02	0,03
08910-A1160X20	A	11,6	18	22	20	medium	4	2	0,02	0,03
08910-A1160X25	A	11,6	18	22	25	long	4	2	0,02	0,03
08910-A1170X12	A	11,7	18	22	12	short	4	2	0,02	0,03
08910-A1170X20	A	11,7	18	22	20	medium	4	2	0,02	0,03
08910-A1170X25	A	11,7	18	22	25	long	4	2	0,02	0,03
08910-A1180X12	A	11,8	18	22	12	short	4	2	0,02	0,03
08910-A1180X20	A	11,8	18	22	20	medium	4	2	0,02	0,03
08910-A1180X25	A	11,8	18	22	25	long	4	2	0,02	0,03
08910-A1190X12	A	11,9	18	22	12	short	4	2	0,02	0,03
08910-A1190X20	A	11,9	18	22	20	medium	4	2	0,02	0,03
08910-A1190X25	A	11,9	18	22	25	long	4	2	0,02	0,03
08910-A1200X12	A	12	18	22	12	short	4	2	0,02	0,03
08910-A1200X20	A	12	18	22	20	medium	4	2	0,02	0,03
08910-A1200X25	A	12	18	22	25	long	4	2	0,02	0,03
08910-A1210X16	A	12,1	22	26	16	short	4	2	0,02	0,03
08910-A1210X28	A	12,1	22	26	28	medium	4	2	0,02	0,03
08910-A1210X36	A	12,1	22	26	36	long	4	2	0,02	0,03
08910-A1220X16	A	12,2	22	26	16	short	4	2	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A1220X28	A	12,2	22	26	28	medium	4	2	0,02	0,03
08910-A1220X36	A	12,2	22	26	36	long	4	2	0,02	0,03
08910-A1230X16	A	12,3	22	26	16	short	4	2	0,02	0,03
08910-A1230X28	A	12,3	22	26	28	medium	4	2	0,02	0,03
08910-A1230X36	A	12,3	22	26	36	long	4	2	0,02	0,03
08910-A1240X16	A	12,4	22	26	16	short	4	2	0,02	0,03
08910-A1240X28	A	12,4	22	26	28	medium	4	2	0,02	0,03
08910-A1240X36	A	12,4	22	26	36	long	4	2	0,02	0,03
08910-A1250X16	A	12,5	22	26	16	short	4	2	0,02	0,03
08910-A1250X28	A	12,5	22	26	28	medium	4	2	0,02	0,03
08910-A1250X36	A	12,5	22	26	36	long	4	2	0,02	0,03
08910-A1260X16	A	12,6	22	26	16	short	4	2	0,02	0,03
08910-A1260X28	A	12,6	22	26	28	medium	4	2	0,02	0,03
08910-A1260X36	A	12,6	22	26	36	long	4	2	0,02	0,03
08910-A1270X16	A	12,7	22	26	16	short	4	2	0,02	0,03
08910-A1270X28	A	12,7	22	26	28	medium	4	2	0,02	0,03
08910-A1270X36	A	12,7	22	26	36	long	4	2	0,02	0,03
08910-A1280X16	A	12,8	22	26	16	short	4	2	0,02	0,03
08910-A1280X28	A	12,8	22	26	28	medium	4	2	0,02	0,03
08910-A1280X36	A	12,8	22	26	36	long	4	2	0,02	0,03
08910-A1290X16	A	12,9	22	26	16	short	4	2	0,02	0,03
08910-A1290X28	A	12,9	22	26	28	medium	4	2	0,02	0,03
08910-A1290X36	A	12,9	22	26	36	long	4	2	0,02	0,03
08910-A1300X16	A	13	22	26	16	short	4	2	0,02	0,03
08910-A1300X28	A	13	22	26	28	medium	4	2	0,02	0,03
08910-A1300X36	A	13	22	26	36	long	4	2	0,02	0,03
08910-A1310X16	A	13,1	22	26	16	short	4	2	0,02	0,03
08910-A1310X28	A	13,1	22	26	28	medium	4	2	0,02	0,03
08910-A1310X36	A	13,1	22	26	36	long	4	2	0,02	0,03
08910-A1320X16	A	13,2	22	26	16	short	4	2	0,02	0,03
08910-A1320X28	A	13,2	22	26	28	medium	4	2	0,02	0,03
08910-A1320X36	A	13,2	22	26	36	long	4	2	0,02	0,03
08910-A1330X16	A	13,3	22	26	16	short	4	2	0,02	0,03
08910-A1330X28	A	13,3	22	26	28	medium	4	2	0,02	0,03
08910-A1330X36	A	13,3	22	26	36	long	4	2	0,02	0,03
08910-A1340X16	A	13,4	22	26	16	short	4	2	0,02	0,03
08910-A1340X28	A	13,4	22	26	28	medium	4	2	0,02	0,03
08910-A1340X36	A	13,4	22	26	36	long	4	2	0,02	0,03
08910-A1350X16	A	13,5	22	26	16	short	4	2	0,02	0,03
08910-A1350X28	A	13,5	22	26	28	medium	4	2	0,02	0,03
08910-A1350X36	A	13,5	22	26	36	long	4	2	0,02	0,03
08910-A1360X16	A	13,6	22	26	16	short	4	2	0,02	0,03
08910-A1360X28	A	13,6	22	26	28	medium	4	2	0,02	0,03
08910-A1360X36	A	13,6	22	26	36	long	4	2	0,02	0,03
08910-A1370X16	A	13,7	22	26	16	short	4	2	0,02	0,03
08910-A1370X28	A	13,7	22	26	28	medium	4	2	0,02	0,03
08910-A1370X36	A	13,7	22	26	36	long	4	2	0,02	0,03
08910-A1380X16	A	13,8	22	26	16	short	4	2	0,02	0,03
08910-A1380X28	A	13,8	22	26	28	medium	4	2	0,02	0,03
08910-A1380X36	A	13,8	22	26	36	long	4	2	0,02	0,03
08910-A1390X16	A	13,9	22	26	16	short	4	2	0,02	0,03
08910-A1390X28	A	13,9	22	26	28	medium	4	2	0,02	0,03
08910-A1390X36	A	13,9	22	26	36	long	4	2	0,02	0,03
08910-A1400X16	A	14	22	26	16	short	4	2	0,02	0,03
08910-A1400X28	A	14	22	26	28	medium	4	2	0,02	0,03
08910-A1400X36	A	14	22	26	36	long	4	2	0,02	0,03
08910-A1410X16	A	14,1	22	26	16	short	4	2	0,02	0,03
08910-A1410X28	A	14,1	22	26	28	medium	4	2	0,02	0,03
08910-A1410X36	A	14,1	22	26	36	long	4	2	0,02	0,03
08910-A1420X16	A	14,2	22	26	16	short	4	2	0,02	0,03
08910-A1420X28	A	14,2	22	26	28	medium	4	2	0,02	0,03
08910-A1420X36	A	14,2	22	26	36	long	4	2	0,02	0,03
08910-A1430X16	A	14,3	22	26	16	short	4	2	0,02	0,03
08910-A1430X28	A	14,3	22	26	28	medium	4	2	0,02	0,03
08910-A1430X36	A	14,3	22	26	36	long	4	2	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A1440X16	A	14,4	22	26	16	short	4	2	0,02	0,03
08910-A1440X28	A	14,4	22	26	28	medium	4	2	0,02	0,03
08910-A1440X36	A	14,4	22	26	36	long	4	2	0,02	0,03
08910-A1450X16	A	14,5	22	26	16	short	4	2	0,02	0,03
08910-A1450X28	A	14,5	22	26	28	medium	4	2	0,02	0,03
08910-A1450X36	A	14,5	22	26	36	long	4	2	0,02	0,03
08910-A1460X16	A	14,6	22	26	16	short	4	2	0,02	0,03
08910-A1460X28	A	14,6	22	26	28	medium	4	2	0,02	0,03
08910-A1460X36	A	14,6	22	26	36	long	4	2	0,02	0,03
08910-A1470X16	A	14,7	22	26	16	short	4	2	0,02	0,03
08910-A1470X28	A	14,7	22	26	28	medium	4	2	0,02	0,03
08910-A1470X36	A	14,7	22	26	36	long	4	2	0,02	0,03
08910-A1480X16	A	14,8	22	26	16	short	4	2	0,02	0,03
08910-A1480X28	A	14,8	22	26	28	medium	4	2	0,02	0,03
08910-A1480X36	A	14,8	22	26	36	long	4	2	0,02	0,03
08910-A1490X16	A	14,9	22	26	16	short	4	2	0,02	0,03
08910-A1490X28	A	14,9	22	26	28	medium	4	2	0,02	0,03
08910-A1490X36	A	14,9	22	26	36	long	4	2	0,02	0,03
08910-A1500X16	A	15	22	26	16	short	4	2	0,02	0,03
08910-A1500X28	A	15	22	26	28	medium	4	2	0,02	0,03
08910-A1500X36	A	15	22	26	36	long	4	2	0,02	0,03
08910-A1550X16	A	15,5	26	30	16	short	4	2	0,02	0,03
08910-A1550X28	A	15,5	26	30	28	medium	4	2	0,02	0,03
08910-A1550X36	A	15,5	26	30	36	long	4	2	0,02	0,03
08910-A1600X16	A	16	26	30	16	short	4	2	0,02	0,03
08910-A1600X28	A	16	26	30	28	medium	4	2	0,02	0,03
08910-A1600X36	A	16	26	30	36	long	4	2	0,02	0,03
08910-A1650X16	A	16,5	26	30	16	short	4	2	0,02	0,03
08910-A1650X28	A	16,5	26	30	28	medium	4	2	0,02	0,03
08910-A1650X36	A	16,5	26	30	36	long	4	2	0,02	0,03
08910-A1700X16	A	17	26	30	16	short	4	2	0,02	0,03
08910-A1700X28	A	17	26	30	28	medium	4	2	0,02	0,03
08910-A1700X36	A	17	26	30	36	long	4	2	0,02	0,03
08910-A1750X16	A	17,5	26	30	16	short	4	2	0,02	0,03
08910-A1750X28	A	17,5	26	30	28	medium	4	2	0,02	0,03
08910-A1750X36	A	17,5	26	30	36	long	4	2	0,02	0,03
08910-A1800X16	A	18	26	30	16	short	4	2	0,02	0,03
08910-A1800X28	A	18	26	30	28	medium	4	2	0,02	0,03
08910-A1800X36	A	18	26	30	36	long	4	2	0,02	0,03
08910-A1850X20	A	18,5	30	34	20	short	5	3	0,02	0,03
08910-A1850X36	A	18,5	30	34	36	medium	5	3	0,02	0,03
08910-A1850X45	A	18,5	30	34	45	long	5	3	0,02	0,03
08910-A1900X20	A	19	30	34	20	short	5	3	0,02	0,03
08910-A1900X36	A	19	30	34	36	medium	5	3	0,02	0,03
08910-A1900X45	A	19	30	34	45	long	5	3	0,02	0,03
08910-A1950X20	A	19,5	30	34	20	short	5	3	0,02	0,03
08910-A1950X36	A	19,5	30	34	36	medium	5	3	0,02	0,03
08910-A1950X45	A	19,5	30	34	45	long	5	3	0,02	0,03
08910-A2000X20	A	20	30	34	20	short	5	3	0,02	0,03
08910-A2000X36	A	20	30	34	36	medium	5	3	0,02	0,03
08910-A2000X45	A	20	30	34	45	long	5	3	0,02	0,03
08910-A2050X20	A	20,5	30	34	20	short	5	3	0,02	0,03
08910-A2050X36	A	20,5	30	34	36	medium	5	3	0,02	0,03
08910-A2050X45	A	20,5	30	34	45	long	5	3	0,02	0,03
08910-A2100X20	A	21	30	34	20	short	5	3	0,02	0,03
08910-A2100X36	A	21	30	34	36	medium	5	3	0,02	0,03
08910-A2100X45	A	21	30	34	45	long	5	3	0,02	0,03
08910-A2150X20	A	21,5	30	34	20	short	5	3	0,02	0,03
08910-A2150X36	A	21,5	30	34	36	medium	5	3	0,02	0,03
08910-A2150X45	A	21,5	30	34	45	long	5	3	0,02	0,03
08910-A2200X20	A	22	30	34	20	short	5	3	0,02	0,03
08910-A2200X36	A	22	30	34	36	medium	5	3	0,02	0,03
08910-A2200X45	A	22	30	34	45	long	5	3	0,02	0,03
08910-A2250X20	A	22,5	35	39	20	short	5	3	0,02	0,05
08910-A2250X36	A	22,5	35	39	36	medium	5	3	0,02	0,05

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A2250X45	A	22,5	35	39	45	long	5	3	0,02	0,05
08910-A2300X20	A	23	35	39	20	short	5	3	0,02	0,05
08910-A2300X36	A	23	35	39	36	medium	5	3	0,02	0,05
08910-A2300X45	A	23	35	39	45	long	5	3	0,02	0,05
08910-A2350X20	A	23,5	35	39	20	short	5	3	0,02	0,05
08910-A2350X36	A	23,5	35	39	36	medium	5	3	0,02	0,05
08910-A2350X45	A	23,5	35	39	45	long	5	3	0,02	0,05
08910-A2400X20	A	24	35	39	20	short	5	3	0,02	0,05
08910-A2400X36	A	24	35	39	36	medium	5	3	0,02	0,05
08910-A2400X45	A	24	35	39	45	long	5	3	0,02	0,05
08910-A2450X20	A	24,5	35	39	20	short	5	3	0,02	0,05
08910-A2450X36	A	24,5	35	39	36	medium	5	3	0,02	0,05
08910-A2450X45	A	24,5	35	39	45	long	5	3	0,02	0,05
08910-A2500X20	A	25	35	39	20	short	5	3	0,02	0,05
08910-A2500X36	A	25	35	39	36	medium	5	3	0,02	0,05
08910-A2500X45	A	25	35	39	45	long	5	3	0,02	0,05
08910-A2550X20	A	25,5	35	39	20	short	5	3	0,02	0,05
08910-A2550X36	A	25,5	35	39	36	medium	5	3	0,02	0,05
08910-A2550X45	A	25,5	35	39	45	long	5	3	0,02	0,05
08910-A2600X20	A	26	35	39	20	short	5	3	0,02	0,05
08910-A2600X36	A	26	35	39	36	medium	5	3	0,02	0,05
08910-A2600X45	A	26	35	39	45	long	5	3	0,02	0,05
08910-A2650X25	A	26,5	42	46	25	short	5	3	0,02	0,05
08910-A2650X45	A	26,5	42	46	45	medium	5	3	0,02	0,05
08910-A2650X56	A	26,5	42	46	56	long	5	3	0,02	0,05
08910-A2700X25	A	27	42	46	25	short	5	3	0,02	0,05
08910-A2700X45	A	27	42	46	45	medium	5	3	0,02	0,05
08910-A2700X56	A	27	42	46	56	long	5	3	0,02	0,05
08910-A2750X25	A	27,5	42	46	25	short	5	3	0,02	0,05
08910-A2750X45	A	27,5	42	46	45	medium	5	3	0,02	0,05
08910-A2750X56	A	27,5	42	46	56	long	5	3	0,02	0,05
08910-A2800X25	A	28	42	46	25	short	5	3	0,02	0,05
08910-A2800X45	A	28	42	46	45	medium	5	3	0,02	0,05
08910-A2800X56	A	28	42	46	56	long	5	3	0,02	0,05
08910-A2850X25	A	28,5	42	46	25	short	5	3	0,02	0,05
08910-A2850X45	A	28,5	42	46	45	medium	5	3	0,02	0,05
08910-A2850X56	A	28,5	42	46	56	long	5	3	0,02	0,05
08910-A2900X25	A	29	42	46	25	short	5	3	0,02	0,05
08910-A2900X45	A	29	42	46	45	medium	5	3	0,02	0,05
08910-A2900X56	A	29	42	46	56	long	5	3	0,02	0,05
08910-A2950X25	A	29,5	42	46	25	short	5	3	0,02	0,05
08910-A2950X45	A	29,5	42	46	45	medium	5	3	0,02	0,05
08910-A2950X56	A	29,5	42	46	56	long	5	3	0,02	0,05
08910-A3000X25	A	30	42	46	25	short	5	3	0,02	0,05
08910-A3000X45	A	30	42	46	45	medium	5	3	0,02	0,05
08910-A3000X56	A	30	42	46	56	long	5	3	0,02	0,05
08910-A3050X25	A	30,5	48	52	25	short	5	3	0,04	0,05
08910-A3050X45	A	30,5	48	52	45	medium	5	3	0,04	0,05
08910-A3050X56	A	30,5	48	52	56	long	5	3	0,04	0,05
08910-A3100X25	A	31	48	52	25	short	5	3	0,04	0,05
08910-A3100X45	A	31	48	52	45	medium	5	3	0,04	0,05
08910-A3100X56	A	31	48	52	56	long	5	3	0,04	0,05
08910-A3150X25	A	31,5	48	52	25	short	5	3	0,04	0,05
08910-A3150X45	A	31,5	48	52	45	medium	5	3	0,04	0,05
08910-A3150X56	A	31,5	48	52	56	long	5	3	0,04	0,05
08910-A3200X25	A	32	48	52	25	short	5	3	0,04	0,05
08910-A3200X45	A	32	48	52	45	medium	5	3	0,04	0,05
08910-A3200X56	A	32	48	52	56	long	5	3	0,04	0,05
08910-A3250X25	A	32,5	48	52	25	short	5	3	0,04	0,05
08910-A3250X45	A	32,5	48	52	45	medium	5	3	0,04	0,05
08910-A3250X56	A	32,5	48	52	56	long	5	3	0,04	0,05
08910-A3300X25	A	33	48	52	25	short	5	3	0,04	0,05
08910-A3300X45	A	33	48	52	45	medium	5	3	0,04	0,05
08910-A3300X56	A	33	48	52	56	long	5	3	0,04	0,05
08910-A3350X25	A	33,5	48	52	25	short	5	3	0,04	0,05

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A3350X45	A	33,5	48	52	45	medium	5	3	0,04	0,05
08910-A3350X56	A	33,5	48	52	56	long	5	3	0,04	0,05
08910-A3400X25	A	34	48	52	25	short	5	3	0,04	0,05
08910-A3400X45	A	34	48	52	45	medium	5	3	0,04	0,05
08910-A3400X56	A	34	48	52	56	long	5	3	0,04	0,05
08910-A3450X25	A	34,5	48	52	25	short	5	3	0,04	0,05
08910-A3450X45	A	34,5	48	52	45	medium	5	3	0,04	0,05
08910-A3450X56	A	34,5	48	52	56	long	5	3	0,04	0,05
08910-A3500X25	A	35	48	52	25	short	5	3	0,04	0,05
08910-A3500X45	A	35	48	52	45	medium	5	3	0,04	0,05
08910-A3500X56	A	35	48	52	56	long	5	3	0,04	0,05
08910-A3550X30	A	35,5	55	59	30	short	5	3,5	0,04	0,05
08910-A3550X56	A	35,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A3550X67	A	35,5	55	59	67	long	5	3,5	0,04	0,05
08910-A3600X30	A	36	55	59	30	short	5	3,5	0,04	0,05
08910-A3600X56	A	36	55	59	56	medium	5	3,5	0,04	0,05
08910-A3600X67	A	36	55	59	67	long	5	3,5	0,04	0,05
08910-A3650X30	A	36,5	55	59	30	short	5	3,5	0,04	0,05
08910-A3650X56	A	36,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A3650X67	A	36,5	55	59	67	long	5	3,5	0,04	0,05
08910-A3700X30	A	37	55	59	30	short	5	3,5	0,04	0,05
08910-A3700X56	A	37	55	59	56	medium	5	3,5	0,04	0,05
08910-A3700X67	A	37	55	59	67	long	5	3,5	0,04	0,05
08910-A3750X30	A	37,5	55	59	30	short	5	3,5	0,04	0,05
08910-A3750X56	A	37,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A3750X67	A	37,5	55	59	67	long	5	3,5	0,04	0,05
08910-A3800X30	A	38	55	59	30	short	5	3,5	0,04	0,05
08910-A3800X56	A	38	55	59	56	medium	5	3,5	0,04	0,05
08910-A3800X67	A	38	55	59	67	long	5	3,5	0,04	0,05
08910-A3850X30	A	38,5	55	59	30	short	5	3,5	0,04	0,05
08910-A3850X56	A	38,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A3850X67	A	38,5	55	59	67	long	5	3,5	0,04	0,05
08910-A3900X30	A	39	55	59	30	short	5	3,5	0,04	0,05
08910-A3900X56	A	39	55	59	56	medium	5	3,5	0,04	0,05
08910-A3900X67	A	39	55	59	67	long	5	3,5	0,04	0,05
08910-A3950X30	A	39,5	55	59	30	short	5	3,5	0,04	0,05
08910-A3950X56	A	39,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A3950X67	A	39,5	55	59	67	long	5	3,5	0,04	0,05
08910-A4000X30	A	40	55	59	30	short	5	3,5	0,04	0,05
08910-A4000X56	A	40	55	59	56	medium	5	3,5	0,04	0,05
08910-A4000X67	A	40	55	59	67	long	5	3,5	0,04	0,05
08910-A4050X30	A	40,5	55	59	30	short	5	3,5	0,04	0,05
08910-A4050X56	A	40,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A4050X67	A	40,5	55	59	67	long	5	3,5	0,04	0,05
08910-A4100X30	A	41	55	59	30	short	5	3,5	0,04	0,05
08910-A4100X56	A	41	55	59	56	medium	5	3,5	0,04	0,05
08910-A4100X67	A	41	55	59	67	long	5	3,5	0,04	0,05
08910-A4150X30	A	41,5	55	59	30	short	5	3,5	0,04	0,05
08910-A4150X56	A	41,5	55	59	56	medium	5	3,5	0,04	0,05
08910-A4150X67	A	41,5	55	59	67	long	5	3,5	0,04	0,05
08910-A4200X30	A	42	55	59	30	short	5	3,5	0,04	0,05
08910-A4200X56	A	42	55	59	56	medium	5	3,5	0,04	0,05
08910-A4200X67	A	42	55	59	67	long	5	3,5	0,04	0,05
08910-A4250X30	A	42,5	62	66	30	short	6	3,5	0,04	0,05
08910-A4250X56	A	42,5	62	66	56	medium	6	3,5	0,04	0,05
08910-A4250X67	A	42,5	62	66	67	long	6	3,5	0,04	0,05
08910-A4300X30	A	43	62	66	30	short	6	3,5	0,04	0,05
08910-A4300X56	A	43	62	66	56	medium	6	3,5	0,04	0,05
08910-A4300X67	A	43	62	66	67	long	6	3,5	0,04	0,05
08910-A4350X30	A	43,5	62	66	30	short	6	3,5	0,04	0,05
08910-A4350X56	A	43,5	62	66	56	medium	6	3,5	0,04	0,05
08910-A4350X67	A	43,5	62	66	67	long	6	3,5	0,04	0,05
08910-A4400X30	A	44	62	66	30	short	6	3,5	0,04	0,05
08910-A4400X56	A	44	62	66	56	medium	6	3,5	0,04	0,05
08910-A4400X67	A	44	62	66	67	long	6	3,5	0,04	0,05

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-A4450X30	A	44,5	62	66	30	short	6	3,5	0,04	0,05
08910-A4450X56	A	44,5	62	66	56	medium	6	3,5	0,04	0,05
08910-A4450X67	A	44,5	62	66	67	long	6	3,5	0,04	0,05
08910-A4500X30	A	45	62	66	30	short	6	3,5	0,04	0,05
08910-A4500X56	A	45	62	66	56	medium	6	3,5	0,04	0,05
08910-A4500X67	A	45	62	66	67	long	6	3,5	0,04	0,05
08910-A4550X30	A	45,5	62	66	30	short	6	3,5	0,04	0,05
08910-A4550X56	A	45,5	62	66	56	medium	6	3,5	0,04	0,05
08910-A4550X67	A	45,5	62	66	67	long	6	3,5	0,04	0,05
08910-A4600X30	A	46	62	66	30	short	6	3,5	0,04	0,05
08910-A4600X56	A	46	62	66	56	medium	6	3,5	0,04	0,05
08910-A4600X67	A	46	62	66	67	long	6	3,5	0,04	0,05
08910-A4650X30	A	46,5	62	66	30	short	6	3,5	0,04	0,05
08910-A4650X56	A	46,5	62	66	56	medium	6	3,5	0,04	0,05
08910-A4650X67	A	46,5	62	66	67	long	6	3,5	0,04	0,05
08910-A4700X30	A	47	62	66	30	short	6	3,5	0,04	0,05
08910-A4700X56	A	47	62	66	56	medium	6	3,5	0,04	0,05
08910-A4700X67	A	47	62	66	67	long	6	3,5	0,04	0,05
08910-A4750X30	A	47,5	62	66	30	short	6	3,5	0,04	0,05
08910-A4750X56	A	47,5	62	66	56	medium	6	3,5	0,04	0,05
08910-A4750X67	A	47,5	62	66	67	long	6	3,5	0,04	0,05
08910-A4800X30	A	48	62	66	30	short	6	3,5	0,04	0,05
08910-A4800X56	A	48	62	66	56	medium	6	3,5	0,04	0,05
08910-A4800X67	A	48	62	66	67	long	6	3,5	0,04	0,05
08910-B0040X06	B	0,4	3	6	6	short	2	1	0,01	0,03
08910-B0060X06	B	0,6	3	6	6	short	2	1	0,01	0,03
08910-B0070X06	B	0,7	3	6	6	short	2	1	0,01	0,03
08910-B0080X06	B	0,8	3	6	6	short	2	1	0,01	0,03
08910-B0090X06	B	0,9	3	6	6	short	2	1	0,01	0,03
08910-B0090X09	B	0,9	3	6	9	medium	2	1	0,01	0,03
08910-B0100X06	B	1	3	6	6	short	2	1	0,01	0,03
08910-B0100X09	B	1	3	6	9	medium	2	1	0,01	0,03
08910-B0110X06	B	1,1	4	7	6	short	2	1	0,01	0,03
08910-B0110X09	B	1,1	4	7	9	medium	2	1	0,01	0,03
08910-B0120X06	B	1,2	4	7	6	short	2	1	0,01	0,03
08910-B0120X09	B	1,2	4	7	9	medium	2	1	0,01	0,03
08910-B0130X06	B	1,3	4	7	6	short	2	1	0,01	0,03
08910-B0130X09	B	1,3	4	7	9	medium	2	1	0,01	0,03
08910-B0140X06	B	1,4	4	7	6	short	2	1	0,01	0,03
08910-B0140X09	B	1,4	4	7	9	medium	2	1	0,01	0,03
08910-B0150X06	B	1,5	4	7	6	short	2	1	0,01	0,03
08910-B0150X09	B	1,5	4	7	9	medium	2	1	0,01	0,03
08910-B0160X06	B	1,6	4	7	6	short	2	1	0,01	0,03
08910-B0160X09	B	1,6	4	7	9	medium	2	1	0,01	0,03
08910-B0170X06	B	1,7	4	7	6	short	2	1	0,01	0,03
08910-B0170X09	B	1,7	4	7	9	medium	2	1	0,01	0,03
08910-B0180X06	B	1,8	4	7	6	short	2	1	0,01	0,03
08910-B0180X09	B	1,8	4	7	9	medium	2	1	0,01	0,03
08910-B0190X06	B	1,9	5	8	6	short	2	1	0,01	0,03
08910-B0190X09	B	1,9	5	8	9	medium	2	1	0,01	0,03
08910-B0200X06	B	2	5	8	6	short	2	1	0,01	0,03
08910-B0200X09	B	2	5	8	9	medium	2	1	0,01	0,03
08910-B0210X06	B	2,1	5	8	6	short	2	1	0,01	0,03
08910-B0210X09	B	2,1	5	8	9	medium	2	1	0,01	0,03
08910-B0220X06	B	2,2	5	8	6	short	2	1	0,01	0,03
08910-B0220X09	B	2,2	5	8	9	medium	2	1	0,01	0,03
08910-B0230X06	B	2,3	5	8	6	short	2	1	0,01	0,03
08910-B0230X09	B	2,3	5	8	9	medium	2	1	0,01	0,03
08910-B0240X06	B	2,4	5	8	6	short	2	1	0,01	0,03
08910-B0240X09	B	2,4	5	8	9	medium	2	1	0,01	0,03
08910-B0250X06	B	2,5	5	8	6	short	2	1	0,01	0,03
08910-B0250X09	B	2,5	5	8	9	medium	2	1	0,01	0,03
08910-B0260X06	B	2,6	5	8	6	short	2	1	0,01	0,03
08910-B0260X09	B	2,6	5	8	9	medium	2	1	0,01	0,03
08910-B0270X08	B	2,7	6	9	8	short	2,5	1	0,01	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B0270X12	B	2,7	6	9	12	medium	2,5	1	0,01	0,03
08910-B0270X16	B	2,7	6	9	16	long	2,5	1	0,01	0,03
08910-B0280X08	B	2,8	6	9	8	short	2,5	1	0,01	0,03
08910-B0280X12	B	2,8	6	9	12	medium	2,5	1	0,01	0,03
08910-B0280X16	B	2,8	6	9	16	long	2,5	1	0,01	0,03
08910-B0290X08	B	2,9	6	9	8	short	2,5	1	0,01	0,03
08910-B0290X12	B	2,9	6	9	12	medium	2,5	1	0,01	0,03
08910-B0290X16	B	2,9	6	9	16	long	2,5	1	0,01	0,03
08910-B0300X08	B	3	6	9	8	short	2,5	1	0,01	0,03
08910-B0300X12	B	3	6	9	12	medium	2,5	1	0,01	0,03
08910-B0300X16	B	3	6	9	16	long	2,5	1	0,01	0,03
08910-B0310X08	B	3,1	6	9	8	short	2,5	1	0,01	0,03
08910-B0310X12	B	3,1	6	9	12	medium	2,5	1	0,01	0,03
08910-B0310X16	B	3,1	6	9	16	long	2,5	1	0,01	0,03
08910-B0320X08	B	3,2	6	9	8	short	2,5	1	0,01	0,03
08910-B0320X12	B	3,2	6	9	12	medium	2,5	1	0,01	0,03
08910-B0320X16	B	3,2	6	9	16	long	2,5	1	0,01	0,03
08910-B0330X08	B	3,3	6	9	8	short	2,5	1	0,01	0,03
08910-B0330X12	B	3,3	6	9	12	medium	2,5	1	0,01	0,03
08910-B0330X16	B	3,3	6	9	16	long	2,5	1	0,01	0,03
08910-B0340X08	B	3,4	7	10	8	short	2,5	1	0,01	0,03
08910-B0340X12	B	3,4	7	10	12	medium	2,5	1	0,01	0,03
08910-B0340X16	B	3,4	7	10	16	long	2,5	1	0,01	0,03
08910-B0350X08	B	3,5	7	10	8	short	2,5	1	0,01	0,03
08910-B0350X12	B	3,5	7	10	12	medium	2,5	1	0,01	0,03
08910-B0350X16	B	3,5	7	10	16	long	2,5	1	0,01	0,03
08910-B0360X08	B	3,6	7	10	8	short	2,5	1	0,01	0,03
08910-B0360X12	B	3,6	7	10	12	medium	2,5	1	0,01	0,03
08910-B0360X16	B	3,6	7	10	16	long	2,5	1	0,01	0,03
08910-B0370X08	B	3,7	7	10	8	short	2,5	1	0,01	0,03
08910-B0370X12	B	3,7	7	10	12	medium	2,5	1	0,01	0,03
08910-B0370X16	B	3,7	7	10	16	long	2,5	1	0,01	0,03
08910-B0380X08	B	3,8	7	10	8	short	2,5	1	0,01	0,03
08910-B0380X12	B	3,8	7	10	12	medium	2,5	1	0,01	0,03
08910-B0380X16	B	3,8	7	10	16	long	2,5	1	0,01	0,03
08910-B0390X08	B	3,9	7	10	8	short	2,5	1	0,01	0,03
08910-B0390X12	B	3,9	7	10	12	medium	2,5	1	0,01	0,03
08910-B0390X16	B	3,9	7	10	16	long	2,5	1	0,01	0,03
08910-B0400X08	B	4	7	10	8	short	2,5	1	0,01	0,03
08910-B0400X12	B	4	7	10	12	medium	2,5	1	0,01	0,03
08910-B0400X16	B	4	7	10	16	long	2,5	1	0,01	0,03
08910-B0410X08	B	4,1	8	11	8	short	2,5	1	0,01	0,03
08910-B0410X12	B	4,1	8	11	12	medium	2,5	1	0,01	0,03
08910-B0410X16	B	4,1	8	11	16	long	2,5	1	0,01	0,03
08910-B0420X08	B	4,2	8	11	8	short	2,5	1	0,01	0,03
08910-B0420X12	B	4,2	8	11	12	medium	2,5	1	0,01	0,03
08910-B0420X16	B	4,2	8	11	16	long	2,5	1	0,01	0,03
08910-B0430X08	B	4,3	8	11	8	short	2,5	1	0,01	0,03
08910-B0430X12	B	4,3	8	11	12	medium	2,5	1	0,01	0,03
08910-B0430X16	B	4,3	8	11	16	long	2,5	1	0,01	0,03
08910-B0440X08	B	4,4	8	11	8	short	2,5	1	0,01	0,03
08910-B0440X12	B	4,4	8	11	12	medium	2,5	1	0,01	0,03
08910-B0440X16	B	4,4	8	11	16	long	2,5	1	0,01	0,03
08910-B0450X08	B	4,5	8	11	8	short	2,5	1	0,01	0,03
08910-B0450X12	B	4,5	8	11	12	medium	2,5	1	0,01	0,03
08910-B0450X16	B	4,5	8	11	16	long	2,5	1	0,01	0,03
08910-B0460X08	B	4,6	8	11	8	short	2,5	1	0,01	0,03
08910-B0460X12	B	4,6	8	11	12	medium	2,5	1	0,01	0,03
08910-B0460X16	B	4,6	8	11	16	long	2,5	1	0,01	0,03
08910-B0470X08	B	4,7	8	11	8	short	2,5	1	0,01	0,03
08910-B0470X12	B	4,7	8	11	12	medium	2,5	1	0,01	0,03
08910-B0470X16	B	4,7	8	11	16	long	2,5	1	0,01	0,03
08910-B0480X08	B	4,8	8	11	8	short	2,5	1	0,01	0,03
08910-B0480X12	B	4,8	8	11	12	medium	2,5	1	0,01	0,03
08910-B0480X16	B	4,8	8	11	16	long	2,5	1	0,01	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B0490X08	B	4,9	8	11	8	short	2,5	1	0,01	0,03
08910-B0490X12	B	4,9	8	11	12	medium	2,5	1	0,01	0,03
08910-B0490X16	B	4,9	8	11	16	long	2,5	1	0,01	0,03
08910-B0500X08	B	5	8	11	8	short	2,5	1	0,01	0,03
08910-B0500X12	B	5	8	11	12	medium	2,5	1	0,01	0,03
08910-B0500X16	B	5	8	11	16	long	2,5	1	0,01	0,03
08910-B0510X10	B	5,1	10	13	10	short	3	1,5	0,02	0,03
08910-B0510X16	B	5,1	10	13	16	medium	3	1,5	0,02	0,03
08910-B0510X20	B	5,1	10	13	20	long	3	1,5	0,02	0,03
08910-B0520X10	B	5,2	10	13	10	short	3	1,5	0,02	0,03
08910-B0520X16	B	5,2	10	13	16	medium	3	1,5	0,02	0,03
08910-B0520X20	B	5,2	10	13	20	long	3	1,5	0,02	0,03
08910-B0530X10	B	5,3	10	13	10	short	3	1,5	0,02	0,03
08910-B0530X16	B	5,3	10	13	16	medium	3	1,5	0,02	0,03
08910-B0530X20	B	5,3	10	13	20	long	3	1,5	0,02	0,03
08910-B0540X10	B	5,4	10	13	10	short	3	1,5	0,02	0,03
08910-B0540X16	B	5,4	10	13	16	medium	3	1,5	0,02	0,03
08910-B0540X20	B	5,4	10	13	20	long	3	1,5	0,02	0,03
08910-B0550X10	B	5,5	10	13	10	short	3	1,5	0,02	0,03
08910-B0550X16	B	5,5	10	13	16	medium	3	1,5	0,02	0,03
08910-B0550X20	B	5,5	10	13	20	long	3	1,5	0,02	0,03
08910-B0560X10	B	5,6	10	13	10	short	3	1,5	0,02	0,03
08910-B0560X16	B	5,6	10	13	16	medium	3	1,5	0,02	0,03
08910-B0560X20	B	5,6	10	13	20	long	3	1,5	0,02	0,03
08910-B0570X10	B	5,7	10	13	10	short	3	1,5	0,02	0,03
08910-B0570X16	B	5,7	10	13	16	medium	3	1,5	0,02	0,03
08910-B0570X20	B	5,7	10	13	20	long	3	1,5	0,02	0,03
08910-B0580X10	B	5,8	10	13	10	short	3	1,5	0,02	0,03
08910-B0580X16	B	5,8	10	13	16	medium	3	1,5	0,02	0,03
08910-B0580X20	B	5,8	10	13	20	long	3	1,5	0,02	0,03
08910-B0590X10	B	5,9	10	13	10	short	3	1,5	0,02	0,03
08910-B0590X16	B	5,9	10	13	16	medium	3	1,5	0,02	0,03
08910-B0590X20	B	5,9	10	13	20	long	3	1,5	0,02	0,03
08910-B0600X10	B	6	10	13	10	short	3	1,5	0,02	0,03
08910-B0600X16	B	6	10	13	16	medium	3	1,5	0,02	0,03
08910-B0600X20	B	6	10	13	20	long	3	1,5	0,02	0,03
08910-B0610X10	B	6,1	12	15	10	short	3	1,5	0,02	0,03
08910-B0610X16	B	6,1	12	15	16	medium	3	1,5	0,02	0,03
08910-B0610X20	B	6,1	12	15	20	long	3	1,5	0,02	0,03
08910-B0620X10	B	6,2	12	15	10	short	3	1,5	0,02	0,03
08910-B0620X16	B	6,2	12	15	16	medium	3	1,5	0,02	0,03
08910-B0620X20	B	6,2	12	15	20	long	3	1,5	0,02	0,03
08910-B0630X10	B	6,3	12	15	10	short	3	1,5	0,02	0,03
08910-B0630X16	B	6,3	12	15	16	medium	3	1,5	0,02	0,03
08910-B0630X20	B	6,3	12	15	20	long	3	1,5	0,02	0,03
08910-B0640X10	B	6,4	12	15	10	short	3	1,5	0,02	0,03
08910-B0640X16	B	6,4	12	15	16	medium	3	1,5	0,02	0,03
08910-B0640X20	B	6,4	12	15	20	long	3	1,5	0,02	0,03
08910-B0650X10	B	6,5	12	15	10	short	3	1,5	0,02	0,03
08910-B0650X16	B	6,5	12	15	16	medium	3	1,5	0,02	0,03
08910-B0650X20	B	6,5	12	15	20	long	3	1,5	0,02	0,03
08910-B0660X10	B	6,6	12	15	10	short	3	1,5	0,02	0,03
08910-B0660X16	B	6,6	12	15	16	medium	3	1,5	0,02	0,03
08910-B0660X20	B	6,6	12	15	20	long	3	1,5	0,02	0,03
08910-B0670X10	B	6,7	12	15	10	short	3	1,5	0,02	0,03
08910-B0670X16	B	6,7	12	15	16	medium	3	1,5	0,02	0,03
08910-B0670X20	B	6,7	12	15	20	long	3	1,5	0,02	0,03
08910-B0680X10	B	6,8	12	15	10	short	3	1,5	0,02	0,03
08910-B0680X16	B	6,8	12	15	16	medium	3	1,5	0,02	0,03
08910-B0680X20	B	6,8	12	15	20	long	3	1,5	0,02	0,03
08910-B0690X10	B	6,9	12	15	10	short	3	1,5	0,02	0,03
08910-B0690X16	B	6,9	12	15	16	medium	3	1,5	0,02	0,03
08910-B0690X20	B	6,9	12	15	20	long	3	1,5	0,02	0,03
08910-B0700X10	B	7	12	15	10	short	3	1,5	0,02	0,03
08910-B0700X16	B	7	12	15	16	medium	3	1,5	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B0700X20	B	7	12	15	20	long	3	1,5	0,02	0,03
08910-B0710X10	B	7,1	12	15	10	short	3	1,5	0,02	0,03
08910-B0710X16	B	7,1	12	15	16	medium	3	1,5	0,02	0,03
08910-B0710X20	B	7,1	12	15	20	long	3	1,5	0,02	0,03
08910-B0720X10	B	7,2	12	15	10	short	3	1,5	0,02	0,03
08910-B0720X16	B	7,2	12	15	16	medium	3	1,5	0,02	0,03
08910-B0720X20	B	7,2	12	15	20	long	3	1,5	0,02	0,03
08910-B0730X10	B	7,3	12	15	10	short	3	1,5	0,02	0,03
08910-B0730X16	B	7,3	12	15	16	medium	3	1,5	0,02	0,03
08910-B0730X20	B	7,3	12	15	20	long	3	1,5	0,02	0,03
08910-B0740X10	B	7,4	12	15	10	short	3	1,5	0,02	0,03
08910-B0740X16	B	7,4	12	15	16	medium	3	1,5	0,02	0,03
08910-B0740X20	B	7,4	12	15	20	long	3	1,5	0,02	0,03
08910-B0750X10	B	7,5	12	15	10	short	3	1,5	0,02	0,03
08910-B0750X16	B	7,5	12	15	16	medium	3	1,5	0,02	0,03
08910-B0750X20	B	7,5	12	15	20	long	3	1,5	0,02	0,03
08910-B0760X10	B	7,6	12	15	10	short	3	1,5	0,02	0,03
08910-B0760X16	B	7,6	12	15	16	medium	3	1,5	0,02	0,03
08910-B0760X20	B	7,6	12	15	20	long	3	1,5	0,02	0,03
08910-B0770X10	B	7,7	12	15	10	short	3	1,5	0,02	0,03
08910-B0770X16	B	7,7	12	15	16	medium	3	1,5	0,02	0,03
08910-B0770X20	B	7,7	12	15	20	long	3	1,5	0,02	0,03
08910-B0780X10	B	7,8	12	15	10	short	3	1,5	0,02	0,03
08910-B0780X16	B	7,8	12	15	16	medium	3	1,5	0,02	0,03
08910-B0780X20	B	7,8	12	15	20	long	3	1,5	0,02	0,03
08910-B0790X10	B	7,9	12	15	10	short	3	1,5	0,02	0,03
08910-B0790X16	B	7,9	12	15	16	medium	3	1,5	0,02	0,03
08910-B0790X20	B	7,9	12	15	20	long	3	1,5	0,02	0,03
08910-B0800X10	B	8	12	15	10	short	3	1,5	0,02	0,03
08910-B0800X16	B	8	12	15	16	medium	3	1,5	0,02	0,03
08910-B0800X20	B	8	12	15	20	long	3	1,5	0,02	0,03
08910-B0810X12	B	8,1	15	18	12	short	3	2	0,02	0,03
08910-B0810X20	B	8,1	15	18	20	medium	3	2	0,02	0,03
08910-B0810X25	B	8,1	15	18	25	long	3	2	0,02	0,03
08910-B0820X12	B	8,2	15	18	12	short	3	2	0,02	0,03
08910-B0820X20	B	8,2	15	18	20	medium	3	2	0,02	0,03
08910-B0820X25	B	8,2	15	18	25	long	3	2	0,02	0,03
08910-B0830X12	B	8,3	15	18	12	short	3	2	0,02	0,03
08910-B0830X20	B	8,3	15	18	20	medium	3	2	0,02	0,03
08910-B0830X25	B	8,3	15	18	25	long	3	2	0,02	0,03
08910-B0840X12	B	8,4	15	18	12	short	3	2	0,02	0,03
08910-B0840X20	B	8,4	15	18	20	medium	3	2	0,02	0,03
08910-B0840X25	B	8,4	15	18	25	long	3	2	0,02	0,03
08910-B0850X12	B	8,5	15	18	12	short	3	2	0,02	0,03
08910-B0850X20	B	8,5	15	18	20	medium	3	2	0,02	0,03
08910-B0850X25	B	8,5	15	18	25	long	3	2	0,02	0,03
08910-B0860X12	B	8,6	15	18	12	short	3	2	0,02	0,03
08910-B0860X20	B	8,6	15	18	20	medium	3	2	0,02	0,03
08910-B0860X25	B	8,6	15	18	25	long	3	2	0,02	0,03
08910-B0870X12	B	8,7	15	18	12	short	3	2	0,02	0,03
08910-B0870X20	B	8,7	15	18	20	medium	3	2	0,02	0,03
08910-B0870X25	B	8,7	15	18	25	long	3	2	0,02	0,03
08910-B0880X12	B	8,8	15	18	12	short	3	2	0,02	0,03
08910-B0880X20	B	8,8	15	18	20	medium	3	2	0,02	0,03
08910-B0880X25	B	8,8	15	18	25	long	3	2	0,02	0,03
08910-B0890X12	B	8,9	15	18	12	short	3	2	0,02	0,03
08910-B0890X20	B	8,9	15	18	20	medium	3	2	0,02	0,03
08910-B0890X25	B	8,9	15	18	25	long	3	2	0,02	0,03
08910-B0900X12	B	9	15	18	12	short	3	2	0,02	0,03
08910-B0900X20	B	9	15	18	20	medium	3	2	0,02	0,03
08910-B0900X25	B	9	15	18	25	long	3	2	0,02	0,03
08910-B0910X12	B	9,1	15	18	12	short	3	2	0,02	0,03
08910-B0910X20	B	9,1	15	18	20	medium	3	2	0,02	0,03
08910-B0910X25	B	9,1	15	18	25	long	3	2	0,02	0,03
08910-B0920X12	B	9,2	15	18	12	short	3	2	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B0920X20	B	9,2	15	18	20	medium	3	2	0,02	0,03
08910-B0920X25	B	9,2	15	18	25	long	3	2	0,02	0,03
08910-B0930X12	B	9,3	15	18	12	short	3	2	0,02	0,03
08910-B0930X20	B	9,3	15	18	20	medium	3	2	0,02	0,03
08910-B0930X25	B	9,3	15	18	25	long	3	2	0,02	0,03
08910-B0940X12	B	9,4	15	18	12	short	3	2	0,02	0,03
08910-B0940X20	B	9,4	15	18	20	medium	3	2	0,02	0,03
08910-B0940X25	B	9,4	15	18	25	long	3	2	0,02	0,03
08910-B0950X12	B	9,5	15	18	12	short	3	2	0,02	0,03
08910-B0950X20	B	9,5	15	18	20	medium	3	2	0,02	0,03
08910-B0950X25	B	9,5	15	18	25	long	3	2	0,02	0,03
08910-B0960X12	B	9,6	15	18	12	short	3	2	0,02	0,03
08910-B0960X20	B	9,6	15	18	20	medium	3	2	0,02	0,03
08910-B0960X25	B	9,6	15	18	25	long	3	2	0,02	0,03
08910-B0970X12	B	9,7	15	18	12	short	3	2	0,02	0,03
08910-B0970X20	B	9,7	15	18	20	medium	3	2	0,02	0,03
08910-B0970X25	B	9,7	15	18	25	long	3	2	0,02	0,03
08910-B0980X12	B	9,8	15	18	12	short	3	2	0,02	0,03
08910-B0980X20	B	9,8	15	18	20	medium	3	2	0,02	0,03
08910-B0980X25	B	9,8	15	18	25	long	3	2	0,02	0,03
08910-B0990X12	B	9,9	15	18	12	short	3	2	0,02	0,03
08910-B0990X20	B	9,9	15	18	20	medium	3	2	0,02	0,03
08910-B0990X25	B	9,9	15	18	25	long	3	2	0,02	0,03
08910-B1000X12	B	10	15	18	12	short	3	2	0,02	0,03
08910-B1000X20	B	10	15	18	20	medium	3	2	0,02	0,03
08910-B1000X25	B	10	15	18	25	long	3	2	0,02	0,03
08910-B1010X12	B	10,1	18	22	12	short	4	2	0,02	0,03
08910-B1010X20	B	10,1	18	22	20	medium	4	2	0,02	0,03
08910-B1010X25	B	10,1	18	22	25	long	4	2	0,02	0,03
08910-B1020X12	B	10,2	18	22	12	short	4	2	0,02	0,03
08910-B1020X20	B	10,2	18	22	20	medium	4	2	0,02	0,03
08910-B1020X25	B	10,2	18	22	25	long	4	2	0,02	0,03
08910-B1030X12	B	10,3	18	22	12	short	4	2	0,02	0,03
08910-B1030X20	B	10,3	18	22	20	medium	4	2	0,02	0,03
08910-B1030X25	B	10,3	18	22	25	long	4	2	0,02	0,03
08910-B1040X12	B	10,4	18	22	12	short	4	2	0,02	0,03
08910-B1040X20	B	10,4	18	22	20	medium	4	2	0,02	0,03
08910-B1040X25	B	10,4	18	22	25	long	4	2	0,02	0,03
08910-B1050X12	B	10,5	18	22	12	short	4	2	0,02	0,03
08910-B1050X20	B	10,5	18	22	20	medium	4	2	0,02	0,03
08910-B1050X25	B	10,5	18	22	25	long	4	2	0,02	0,03
08910-B1060X12	B	10,6	18	22	12	short	4	2	0,02	0,03
08910-B1060X20	B	10,6	18	22	20	medium	4	2	0,02	0,03
08910-B1060X25	B	10,6	18	22	25	long	4	2	0,02	0,03
08910-B1070X12	B	10,7	18	22	12	short	4	2	0,02	0,03
08910-B1070X20	B	10,7	18	22	20	medium	4	2	0,02	0,03
08910-B1070X25	B	10,7	18	22	25	long	4	2	0,02	0,03
08910-B1080X12	B	10,8	18	22	12	short	4	2	0,02	0,03
08910-B1080X20	B	10,8	18	22	20	medium	4	2	0,02	0,03
08910-B1080X25	B	10,8	18	22	25	long	4	2	0,02	0,03
08910-B1090X12	B	10,9	18	22	12	short	4	2	0,02	0,03
08910-B1090X20	B	10,9	18	22	20	medium	4	2	0,02	0,03
08910-B1090X25	B	10,9	18	22	25	long	4	2	0,02	0,03
08910-B1100X12	B	11	18	22	12	short	4	2	0,02	0,03
08910-B1100X20	B	11	18	22	20	medium	4	2	0,02	0,03
08910-B1100X25	B	11	18	22	25	long	4	2	0,02	0,03
08910-B1110X12	B	11,1	18	22	12	short	4	2	0,02	0,03
08910-B1110X20	B	11,1	18	22	20	medium	4	2	0,02	0,03
08910-B1110X25	B	11,1	18	22	25	long	4	2	0,02	0,03
08910-B1120X12	B	11,2	18	22	12	short	4	2	0,02	0,03
08910-B1120X20	B	11,2	18	22	20	medium	4	2	0,02	0,03
08910-B1120X25	B	11,2	18	22	25	long	4	2	0,02	0,03
08910-B1130X12	B	11,3	18	22	12	short	4	2	0,02	0,03
08910-B1130X20	B	11,3	18	22	20	medium	4	2	0,02	0,03
08910-B1130X25	B	11,3	18	22	25	long	4	2	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B1140X12	B	11,4	18	22	12	short	4	2	0,02	0,03
08910-B1140X20	B	11,4	18	22	20	medium	4	2	0,02	0,03
08910-B1140X25	B	11,4	18	22	25	long	4	2	0,02	0,03
08910-B1150X12	B	11,5	18	22	12	short	4	2	0,02	0,03
08910-B1150X20	B	11,5	18	22	20	medium	4	2	0,02	0,03
08910-B1150X25	B	11,5	18	22	25	long	4	2	0,02	0,03
08910-B1160X12	B	11,6	18	22	12	short	4	2	0,02	0,03
08910-B1160X20	B	11,6	18	22	20	medium	4	2	0,02	0,03
08910-B1160X25	B	11,6	18	22	25	long	4	2	0,02	0,03
08910-B1170X12	B	11,7	18	22	12	short	4	2	0,02	0,03
08910-B1170X20	B	11,7	18	22	20	medium	4	2	0,02	0,03
08910-B1170X25	B	11,7	18	22	25	long	4	2	0,02	0,03
08910-B1180X12	B	11,8	18	22	12	short	4	2	0,02	0,03
08910-B1180X20	B	11,8	18	22	20	medium	4	2	0,02	0,03
08910-B1180X25	B	11,8	18	22	25	long	4	2	0,02	0,03
08910-B1190X12	B	11,9	18	22	12	short	4	2	0,02	0,03
08910-B1190X20	B	11,9	18	22	20	medium	4	2	0,02	0,03
08910-B1190X25	B	11,9	18	22	25	long	4	2	0,02	0,03
08910-B1200X12	B	12	18	22	12	short	4	2	0,02	0,03
08910-B1200X20	B	12	18	22	20	medium	4	2	0,02	0,03
08910-B1200X25	B	12	18	22	25	long	4	2	0,02	0,03
08910-B1210X16	B	12,1	22	26	16	short	4	2	0,02	0,03
08910-B1210X28	B	12,1	22	26	28	medium	4	2	0,02	0,03
08910-B1210X36	B	12,1	22	26	36	long	4	2	0,02	0,03
08910-B1220X16	B	12,2	22	26	16	short	4	2	0,02	0,03
08910-B1220X28	B	12,2	22	26	28	medium	4	2	0,02	0,03
08910-B1220X36	B	12,2	22	26	36	long	4	2	0,02	0,03
08910-B1230X16	B	12,3	22	26	16	short	4	2	0,02	0,03
08910-B1230X28	B	12,3	22	26	28	medium	4	2	0,02	0,03
08910-B1230X36	B	12,3	22	26	36	long	4	2	0,02	0,03
08910-B1240X16	B	12,4	22	26	16	short	4	2	0,02	0,03
08910-B1240X28	B	12,4	22	26	28	medium	4	2	0,02	0,03
08910-B1240X36	B	12,4	22	26	36	long	4	2	0,02	0,03
08910-B1250X16	B	12,5	22	26	16	short	4	2	0,02	0,03
08910-B1250X28	B	12,5	22	26	28	medium	4	2	0,02	0,03
08910-B1250X36	B	12,5	22	26	36	long	4	2	0,02	0,03
08910-B1260X16	B	12,6	22	26	16	short	4	2	0,02	0,03
08910-B1260X28	B	12,6	22	26	28	medium	4	2	0,02	0,03
08910-B1260X36	B	12,6	22	26	36	long	4	2	0,02	0,03
08910-B1270X16	B	12,7	22	26	16	short	4	2	0,02	0,03
08910-B1270X28	B	12,7	22	26	28	medium	4	2	0,02	0,03
08910-B1270X36	B	12,7	22	26	36	long	4	2	0,02	0,03
08910-B1280X16	B	12,8	22	26	16	short	4	2	0,02	0,03
08910-B1280X28	B	12,8	22	26	28	medium	4	2	0,02	0,03
08910-B1280X36	B	12,8	22	26	36	long	4	2	0,02	0,03
08910-B1290X16	B	12,9	22	26	16	short	4	2	0,02	0,03
08910-B1290X28	B	12,9	22	26	28	medium	4	2	0,02	0,03
08910-B1290X36	B	12,9	22	26	36	long	4	2	0,02	0,03
08910-B1300X16	B	13	22	26	16	short	4	2	0,02	0,03
08910-B1300X28	B	13	22	26	28	medium	4	2	0,02	0,03
08910-B1300X36	B	13	22	26	36	long	4	2	0,02	0,03
08910-B1310X16	B	13,1	22	26	16	short	4	2	0,02	0,03
08910-B1310X28	B	13,1	22	26	28	medium	4	2	0,02	0,03
08910-B1310X36	B	13,1	22	26	36	long	4	2	0,02	0,03
08910-B1320X16	B	13,2	22	26	16	short	4	2	0,02	0,03
08910-B1320X28	B	13,2	22	26	28	medium	4	2	0,02	0,03
08910-B1320X36	B	13,2	22	26	36	long	4	2	0,02	0,03
08910-B1330X16	B	13,3	22	26	16	short	4	2	0,02	0,03
08910-B1330X28	B	13,3	22	26	28	medium	4	2	0,02	0,03
08910-B1330X36	B	13,3	22	26	36	long	4	2	0,02	0,03
08910-B1340X16	B	13,4	22	26	16	short	4	2	0,02	0,03
08910-B1340X28	B	13,4	22	26	28	medium	4	2	0,02	0,03
08910-B1340X36	B	13,4	22	26	36	long	4	2	0,02	0,03
08910-B1350X16	B	13,5	22	26	16	short	4	2	0,02	0,03
08910-B1350X28	B	13,5	22	26	28	medium	4	2	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B1350X36	B	13,5	22	26	36	long	4	2	0,02	0,03
08910-B1360X16	B	13,6	22	26	16	short	4	2	0,02	0,03
08910-B1360X28	B	13,6	22	26	28	medium	4	2	0,02	0,03
08910-B1360X36	B	13,6	22	26	36	long	4	2	0,02	0,03
08910-B1370X16	B	13,7	22	26	16	short	4	2	0,02	0,03
08910-B1370X28	B	13,7	22	26	28	medium	4	2	0,02	0,03
08910-B1370X36	B	13,7	22	26	36	long	4	2	0,02	0,03
08910-B1380X16	B	13,8	22	26	16	short	4	2	0,02	0,03
08910-B1380X28	B	13,8	22	26	28	medium	4	2	0,02	0,03
08910-B1380X36	B	13,8	22	26	36	long	4	2	0,02	0,03
08910-B1390X16	B	13,9	22	26	16	short	4	2	0,02	0,03
08910-B1390X28	B	13,9	22	26	28	medium	4	2	0,02	0,03
08910-B1390X36	B	13,9	22	26	36	long	4	2	0,02	0,03
08910-B1400X16	B	14	22	26	16	short	4	2	0,02	0,03
08910-B1400X28	B	14	22	26	28	medium	4	2	0,02	0,03
08910-B1400X36	B	14	22	26	36	long	4	2	0,02	0,03
08910-B1410X16	B	14,1	22	26	16	short	4	2	0,02	0,03
08910-B1410X28	B	14,1	22	26	28	medium	4	2	0,02	0,03
08910-B1410X36	B	14,1	22	26	36	long	4	2	0,02	0,03
08910-B1420X16	B	14,2	22	26	16	short	4	2	0,02	0,03
08910-B1420X28	B	14,2	22	26	28	medium	4	2	0,02	0,03
08910-B1420X36	B	14,2	22	26	36	long	4	2	0,02	0,03
08910-B1430X16	B	14,3	22	26	16	short	4	2	0,02	0,03
08910-B1430X28	B	14,3	22	26	28	medium	4	2	0,02	0,03
08910-B1430X36	B	14,3	22	26	36	long	4	2	0,02	0,03
08910-B1440X16	B	14,4	22	26	16	short	4	2	0,02	0,03
08910-B1440X28	B	14,4	22	26	28	medium	4	2	0,02	0,03
08910-B1440X36	B	14,4	22	26	36	long	4	2	0,02	0,03
08910-B1450X16	B	14,5	22	26	16	short	4	2	0,02	0,03
08910-B1450X28	B	14,5	22	26	28	medium	4	2	0,02	0,03
08910-B1450X36	B	14,5	22	26	36	long	4	2	0,02	0,03
08910-B1460X16	B	14,6	22	26	16	short	4	2	0,02	0,03
08910-B1460X28	B	14,6	22	26	28	medium	4	2	0,02	0,03
08910-B1460X36	B	14,6	22	26	36	long	4	2	0,02	0,03
08910-B1470X16	B	14,7	22	26	16	short	4	2	0,02	0,03
08910-B1470X28	B	14,7	22	26	28	medium	4	2	0,02	0,03
08910-B1470X36	B	14,7	22	26	36	long	4	2	0,02	0,03
08910-B1480X16	B	14,8	22	26	16	short	4	2	0,02	0,03
08910-B1480X28	B	14,8	22	26	28	medium	4	2	0,02	0,03
08910-B1480X36	B	14,8	22	26	36	long	4	2	0,02	0,03
08910-B1490X16	B	14,9	22	26	16	short	4	2	0,02	0,03
08910-B1490X28	B	14,9	22	26	28	medium	4	2	0,02	0,03
08910-B1490X36	B	14,9	22	26	36	long	4	2	0,02	0,03
08910-B1500X16	B	15	22	26	16	short	4	2	0,02	0,03
08910-B1500X28	B	15	22	26	28	medium	4	2	0,02	0,03
08910-B1500X36	B	15	22	26	36	long	4	2	0,02	0,03
08910-B1550X16	B	15,5	26	30	16	short	4	2	0,02	0,03
08910-B1550X28	B	15,5	26	30	28	medium	4	2	0,02	0,03
08910-B1550X36	B	15,5	26	30	36	long	4	2	0,02	0,03
08910-B1600X16	B	16	26	30	16	short	4	2	0,02	0,03
08910-B1600X28	B	16	26	30	28	medium	4	2	0,02	0,03
08910-B1600X36	B	16	26	30	36	long	4	2	0,02	0,03
08910-B1650X16	B	16,5	26	30	16	short	4	2	0,02	0,03
08910-B1650X28	B	16,5	26	30	28	medium	4	2	0,02	0,03
08910-B1650X36	B	16,5	26	30	36	long	4	2	0,02	0,03
08910-B1700X16	B	17	26	30	16	short	4	2	0,02	0,03
08910-B1700X28	B	17	26	30	28	medium	4	2	0,02	0,03
08910-B1700X36	B	17	26	30	36	long	4	2	0,02	0,03
08910-B1750X16	B	17,5	26	30	16	short	4	2	0,02	0,03
08910-B1750X28	B	17,5	26	30	28	medium	4	2	0,02	0,03
08910-B1750X36	B	17,5	26	30	36	long	4	2	0,02	0,03
08910-B1800X16	B	18	26	30	16	short	4	2	0,02	0,03
08910-B1800X28	B	18	26	30	28	medium	4	2	0,02	0,03
08910-B1800X36	B	18	26	30	36	long	4	2	0,02	0,03
08910-B1850X20	B	18,5	30	34	20	short	5	3	0,02	0,03

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B1850X36	B	18,5	30	34	36	medium	5	3	0,02	0,03
08910-B1850X45	B	18,5	30	34	45	long	5	3	0,02	0,03
08910-B1900X20	B	19	30	34	20	short	5	3	0,02	0,03
08910-B1900X36	B	19	30	34	36	medium	5	3	0,02	0,03
08910-B1900X45	B	19	30	34	45	long	5	3	0,02	0,03
08910-B1950X20	B	19,5	30	34	20	short	5	3	0,02	0,03
08910-B1950X36	B	19,5	30	34	36	medium	5	3	0,02	0,03
08910-B1950X45	B	19,5	30	34	45	long	5	3	0,02	0,03
08910-B2000X20	B	20	30	34	20	short	5	3	0,02	0,03
08910-B2000X36	B	20	30	34	36	medium	5	3	0,02	0,03
08910-B2000X45	B	20	30	34	45	long	5	3	0,02	0,03
08910-B2050X20	B	20,5	30	34	20	short	5	3	0,02	0,03
08910-B2050X36	B	20,5	30	34	36	medium	5	3	0,02	0,03
08910-B2050X45	B	20,5	30	34	45	long	5	3	0,02	0,03
08910-B2100X20	B	21	30	34	20	short	5	3	0,02	0,03
08910-B2100X36	B	21	30	34	36	medium	5	3	0,02	0,03
08910-B2100X45	B	21	30	34	45	long	5	3	0,02	0,03
08910-B2150X20	B	21,5	30	34	20	short	5	3	0,02	0,03
08910-B2150X36	B	21,5	30	34	36	medium	5	3	0,02	0,03
08910-B2150X45	B	21,5	30	34	45	long	5	3	0,02	0,03
08910-B2200X20	B	22	30	34	20	short	5	3	0,02	0,03
08910-B2200X36	B	22	30	34	36	medium	5	3	0,02	0,03
08910-B2200X45	B	22	30	34	45	long	5	3	0,02	0,03
08910-B2250X20	B	22,5	35	39	20	short	5	3	0,02	0,05
08910-B2250X36	B	22,5	35	39	36	medium	5	3	0,02	0,05
08910-B2250X45	B	22,5	35	39	45	long	5	3	0,02	0,05
08910-B2300X20	B	23	35	39	20	short	5	3	0,02	0,05
08910-B2300X36	B	23	35	39	36	medium	5	3	0,02	0,05
08910-B2300X45	B	23	35	39	45	long	5	3	0,02	0,05
08910-B2350X20	B	23,5	35	39	20	short	5	3	0,02	0,05
08910-B2350X36	B	23,5	35	39	36	medium	5	3	0,02	0,05
08910-B2350X45	B	23,5	35	39	45	long	5	3	0,02	0,05
08910-B2400X20	B	24	35	39	20	short	5	3	0,02	0,05
08910-B2400X36	B	24	35	39	36	medium	5	3	0,02	0,05
08910-B2400X45	B	24	35	39	45	long	5	3	0,02	0,05
08910-B2450X20	B	24,5	35	39	20	short	5	3	0,02	0,05
08910-B2450X36	B	24,5	35	39	36	medium	5	3	0,02	0,05
08910-B2450X45	B	24,5	35	39	45	long	5	3	0,02	0,05
08910-B2500X20	B	25	35	39	20	short	5	3	0,02	0,05
08910-B2500X36	B	25	35	39	36	medium	5	3	0,02	0,05
08910-B2500X45	B	25	35	39	45	long	5	3	0,02	0,05
08910-B2550X20	B	25,5	35	39	20	short	5	3	0,02	0,05
08910-B2550X36	B	25,5	35	39	36	medium	5	3	0,02	0,05
08910-B2550X45	B	25,5	35	39	45	long	5	3	0,02	0,05
08910-B2600X20	B	26	35	39	20	short	5	3	0,02	0,05
08910-B2600X36	B	26	35	39	36	medium	5	3	0,02	0,05
08910-B2600X45	B	26	35	39	45	long	5	3	0,02	0,05
08910-B2650X25	B	26,5	42	46	25	short	5	3	0,02	0,05
08910-B2650X45	B	26,5	42	46	45	medium	5	3	0,02	0,05
08910-B2650X56	B	26,5	42	46	56	long	5	3	0,02	0,05
08910-B2700X25	B	27	42	46	25	short	5	3	0,02	0,05
08910-B2700X45	B	27	42	46	45	medium	5	3	0,02	0,05
08910-B2700X56	B	27	42	46	56	long	5	3	0,02	0,05
08910-B2750X25	B	27,5	42	46	25	short	5	3	0,02	0,05
08910-B2750X45	B	27,5	42	46	45	medium	5	3	0,02	0,05
08910-B2750X56	B	27,5	42	46	56	long	5	3	0,02	0,05
08910-B2800X25	B	28	42	46	25	short	5	3	0,02	0,05
08910-B2800X45	B	28	42	46	45	medium	5	3	0,02	0,05
08910-B2800X56	B	28	42	46	56	long	5	3	0,02	0,05
08910-B2850X25	B	28,5	42	46	25	short	5	3	0,02	0,05
08910-B2850X45	B	28,5	42	46	45	medium	5	3	0,02	0,05
08910-B2850X56	B	28,5	42	46	56	long	5	3	0,02	0,05
08910-B2900X25	B	29	42	46	25	short	5	3	0,02	0,05
08910-B2900X45	B	29	42	46	45	medium	5	3	0,02	0,05
08910-B2900X56	B	29	42	46	56	long	5	3	0,02	0,05

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B2950X25	B	29,5	42	46	25	short	5	3	0,02	0,05
08910-B2950X45	B	29,5	42	46	45	medium	5	3	0,02	0,05
08910-B2950X56	B	29,5	42	46	56	long	5	3	0,02	0,05
08910-B3000X25	B	30	42	46	25	short	5	3	0,02	0,05
08910-B3000X45	B	30	42	46	45	medium	5	3	0,02	0,05
08910-B3000X56	B	30	42	46	56	long	5	3	0,02	0,05
08910-B3050X25	B	30,5	48	52	25	short	5	3	0,04	0,05
08910-B3050X45	B	30,5	48	52	45	medium	5	3	0,04	0,05
08910-B3050X56	B	30,5	48	52	56	long	5	3	0,04	0,05
08910-B3100X25	B	31	48	52	25	short	5	3	0,04	0,05
08910-B3100X45	B	31	48	52	45	medium	5	3	0,04	0,05
08910-B3100X56	B	31	48	52	56	long	5	3	0,04	0,05
08910-B3150X25	B	31,5	48	52	25	short	5	3	0,04	0,05
08910-B3150X45	B	31,5	48	52	45	medium	5	3	0,04	0,05
08910-B3150X56	B	31,5	48	52	56	long	5	3	0,04	0,05
08910-B3200X25	B	32	48	52	25	short	5	3	0,04	0,05
08910-B3200X45	B	32	48	52	45	medium	5	3	0,04	0,05
08910-B3200X56	B	32	48	52	56	long	5	3	0,04	0,05
08910-B3250X25	B	32,5	48	52	25	short	5	3	0,04	0,05
08910-B3250X45	B	32,5	48	52	45	medium	5	3	0,04	0,05
08910-B3250X56	B	32,5	48	52	56	long	5	3	0,04	0,05
08910-B3300X25	B	33	48	52	25	short	5	3	0,04	0,05
08910-B3300X45	B	33	48	52	45	medium	5	3	0,04	0,05
08910-B3300X56	B	33	48	52	56	long	5	3	0,04	0,05
08910-B3350X25	B	33,5	48	52	25	short	5	3	0,04	0,05
08910-B3350X45	B	33,5	48	52	45	medium	5	3	0,04	0,05
08910-B3350X56	B	33,5	48	52	56	long	5	3	0,04	0,05
08910-B3400X25	B	34	48	52	25	short	5	3	0,04	0,05
08910-B3400X45	B	34	48	52	45	medium	5	3	0,04	0,05
08910-B3400X56	B	34	48	52	56	long	5	3	0,04	0,05
08910-B3450X25	B	34,5	48	52	25	short	5	3	0,04	0,05
08910-B3450X45	B	34,5	48	52	45	medium	5	3	0,04	0,05
08910-B3450X56	B	34,5	48	52	56	long	5	3	0,04	0,05
08910-B3500X25	B	35	48	52	25	short	5	3	0,04	0,05
08910-B3500X45	B	35	48	52	45	medium	5	3	0,04	0,05
08910-B3500X56	B	35	48	52	56	long	5	3	0,04	0,05
08910-B3550X30	B	35,5	55	59	30	short	5	3,5	0,04	0,05
08910-B3550X56	B	35,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B3550X67	B	35,5	55	59	67	long	5	3,5	0,04	0,05
08910-B3600X30	B	36	55	59	30	short	5	3,5	0,04	0,05
08910-B3600X56	B	36	55	59	56	medium	5	3,5	0,04	0,05
08910-B3600X67	B	36	55	59	67	long	5	3,5	0,04	0,05
08910-B3650X30	B	36,5	55	59	30	short	5	3,5	0,04	0,05
08910-B3650X56	B	36,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B3650X67	B	36,5	55	59	67	long	5	3,5	0,04	0,05
08910-B3700X30	B	37	55	59	30	short	5	3,5	0,04	0,05
08910-B3700X56	B	37	55	59	56	medium	5	3,5	0,04	0,05
08910-B3700X67	B	37	55	59	67	long	5	3,5	0,04	0,05
08910-B3750X30	B	37,5	55	59	30	short	5	3,5	0,04	0,05
08910-B3750X56	B	37,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B3750X67	B	37,5	55	59	67	long	5	3,5	0,04	0,05
08910-B3800X30	B	38	55	59	30	short	5	3,5	0,04	0,05
08910-B3800X56	B	38	55	59	56	medium	5	3,5	0,04	0,05
08910-B3800X67	B	38	55	59	67	long	5	3,5	0,04	0,05
08910-B3850X30	B	38,5	55	59	30	short	5	3,5	0,04	0,05
08910-B3850X56	B	38,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B3850X67	B	38,5	55	59	67	long	5	3,5	0,04	0,05
08910-B3900X30	B	39	55	59	30	short	5	3,5	0,04	0,05
08910-B3900X56	B	39	55	59	56	medium	5	3,5	0,04	0,05
08910-B3900X67	B	39	55	59	67	long	5	3,5	0,04	0,05
08910-B3950X30	B	39,5	55	59	30	short	5	3,5	0,04	0,05
08910-B3950X56	B	39,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B3950X67	B	39,5	55	59	67	long	5	3,5	0,04	0,05
08910-B4000X30	B	40	55	59	30	short	5	3,5	0,04	0,05
08910-B4000X56	B	40	55	59	56	medium	5	3,5	0,04	0,05

Overview of items

Order No.	Form	D1	D2	D3	L1	Product type	L2	R	T1	T2
08910-B4000X67	B	40	55	59	67	long	5	3,5	0,04	0,05
08910-B4050X30	B	40,5	55	59	30	short	5	3,5	0,04	0,05
08910-B4050X56	B	40,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B4050X67	B	40,5	55	59	67	long	5	3,5	0,04	0,05
08910-B4100X30	B	41	55	59	30	short	5	3,5	0,04	0,05
08910-B4100X56	B	41	55	59	56	medium	5	3,5	0,04	0,05
08910-B4100X67	B	41	55	59	67	long	5	3,5	0,04	0,05
08910-B4150X30	B	41,5	55	59	30	short	5	3,5	0,04	0,05
08910-B4150X56	B	41,5	55	59	56	medium	5	3,5	0,04	0,05
08910-B4150X67	B	41,5	55	59	67	long	5	3,5	0,04	0,05
08910-B4200X30	B	42	55	59	30	short	5	3,5	0,04	0,05
08910-B4200X56	B	42	55	59	56	medium	5	3,5	0,04	0,05
08910-B4200X67	B	42	55	59	67	long	5	3,5	0,04	0,05
08910-B4250X30	B	42,5	62	66	30	short	6	3,5	0,04	0,05
08910-B4250X56	B	42,5	62	66	56	medium	6	3,5	0,04	0,05
08910-B4250X67	B	42,5	62	66	67	long	6	3,5	0,04	0,05
08910-B4300X30	B	43	62	66	30	short	6	3,5	0,04	0,05
08910-B4300X56	B	43	62	66	56	medium	6	3,5	0,04	0,05
08910-B4300X67	B	43	62	66	67	long	6	3,5	0,04	0,05
08910-B4350X30	B	43,5	62	66	30	short	6	3,5	0,04	0,05
08910-B4350X56	B	43,5	62	66	56	medium	6	3,5	0,04	0,05
08910-B4350X67	B	43,5	62	66	67	long	6	3,5	0,04	0,05
08910-B4400X30	B	44	62	66	30	short	6	3,5	0,04	0,05
08910-B4400X56	B	44	62	66	56	medium	6	3,5	0,04	0,05
08910-B4400X67	B	44	62	66	67	long	6	3,5	0,04	0,05
08910-B4450X30	B	44,5	62	66	30	short	6	3,5	0,04	0,05
08910-B4450X56	B	44,5	62	66	56	medium	6	3,5	0,04	0,05
08910-B4450X67	B	44,5	62	66	67	long	6	3,5	0,04	0,05
08910-B4500X30	B	45	62	66	30	short	6	3,5	0,04	0,05
08910-B4500X56	B	45	62	66	56	medium	6	3,5	0,04	0,05
08910-B4500X67	B	45	62	66	67	long	6	3,5	0,04	0,05
08910-B4550X30	B	45,5	62	66	30	short	6	3,5	0,04	0,05
08910-B4550X56	B	45,5	62	66	56	medium	6	3,5	0,04	0,05
08910-B4550X67	B	45,5	62	66	67	long	6	3,5	0,04	0,05
08910-B4600X30	B	46	62	66	30	short	6	3,5	0,04	0,05
08910-B4600X56	B	46	62	66	56	medium	6	3,5	0,04	0,05
08910-B4600X67	B	46	62	66	67	long	6	3,5	0,04	0,05
08910-B4650X30	B	46,5	62	66	30	short	6	3,5	0,04	0,05
08910-B4650X56	B	46,5	62	66	56	medium	6	3,5	0,04	0,05
08910-B4650X67	B	46,5	62	66	67	long	6	3,5	0,04	0,05
08910-B4700X30	B	47	62	66	30	short	6	3,5	0,04	0,05
08910-B4700X56	B	47	62	66	56	medium	6	3,5	0,04	0,05
08910-B4700X67	B	47	62	66	67	long	6	3,5	0,04	0,05
08910-B4750X30	B	47,5	62	66	30	short	6	3,5	0,04	0,05
08910-B4750X56	B	47,5	62	66	56	medium	6	3,5	0,04	0,05
08910-B4750X67	B	47,5	62	66	67	long	6	3,5	0,04	0,05
08910-B4800X30	B	48	62	66	30	short	6	3,5	0,04	0,05
08910-B4800X56	B	48	62	66	56	medium	6	3,5	0,04	0,05
08910-B4800X67	B	48	62	66	67	long	6	3,5	0,04	0,05

Information about this article

DIN 172 flanged drill bushes The drill bushes from norelem are robust and available in a wide range of variations so that you can always choose the drill bush that best suits your application. The DIN 172 drill bushes can be used e.g. in drilling jigs as a drill bit guide, or as a hole

Information about this article

reinforcement in soft materials so that the required hole form is maintained. DIN 172 drill bushes are made from a special low carbon steel and are available in Forms A and B. They are hardened to 740 ± 80 HV 10 and ground to ensure precision and long life. The bushes come in size increments of 0.1 mm up to 15 mm diameter – between 15 and 48 mm they come in size increments of 0.5 mm.