

Item description/product images



Description

Material:
NdFeB N35 (neodymium).

Version:
nickel-plated.


Note:
Unshielded system.

Temperature range:
max. 80°C.

Assembly:
The magnets can be mounted by press-fit or gluing.

Drawing reference:
1) magnetic face

Drawings

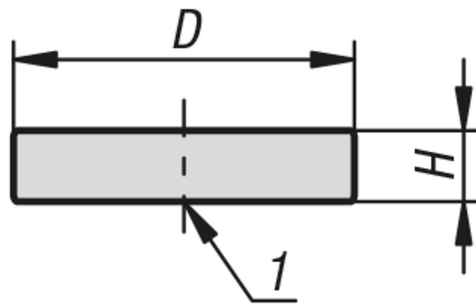

Overview of items

| Order No. | D | H | Magnetic force N |
|-----------|---------|--------|------------------|
| 09000-05 | 5 ±0,1 | 3 ±0,1 | 5 |
| 09000-06 | 6 ±0,1 | 3 ±0,1 | 7,5 |
| 09000-08 | 8 ±0,1 | 4 ±0,1 | 13 |
| 09000-10 | 10 ±0,1 | 3 ±0,1 | 15 |
| 09000-12 | 12 ±0,1 | 3 ±0,1 | 20 |
| 09000-15 | 15 ±0,1 | 3 ±0,1 | 25 |
| 09000-18 | 18 ±0,1 | 3 ±0,1 | 33 |
| 09000-24 | 24 ±0,1 | 3 ±0,1 | 39 |