

Item description/product images



Description

Material:

Thermoset PF 31.
Steel or stainless steel.


Version:

Thermoset black, high-gloss polished.
Trivalent blue passivated steel or bright stainless steel.

On request:

Other screw lengths.

Drawings

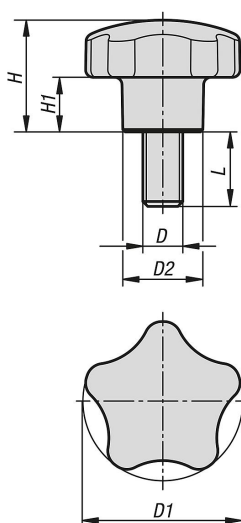

Overview of items

Order No.	Component material	D	D1	D2	H	H1	L
06851-01-3206X10	steel	M6	32	16	22,5	11	10
06851-01-3206X15	steel	M6	32	16	22,5	11	15
06851-01-3206X20	steel	M6	32	16	22,5	11	20
06851-01-3206X35	steel	M6	32	16	22,5	11	35
06851-01-3208X15	steel	M8	32	16	22,5	11	15
06851-01-3208X25	steel	M8	32	16	22,5	11	25
06851-01-4006X15	steel	M6	40	20	28	14	15
06851-01-4008X15	steel	M8	40	20	28	14	15
06851-01-4008X20	steel	M8	40	20	28	14	20
06851-01-4008X25	steel	M8	40	20	28	14	25
06851-01-4008X30	steel	M8	40	20	28	14	30
06851-01-4008X35	steel	M8	40	20	28	14	35
06851-01-4008X45	steel	M8	40	20	28	14	45
06851-01-4010X30	steel	M10	40	20	28	14	30
06851-01-5008X15	steel	M8	50	25	35	17,5	15
06851-01-5008X25	steel	M8	50	25	35	17,5	25
06851-01-5010X20	steel	M10	50	25	35	17,5	20
06851-01-5010X30	steel	M10	50	25	35	17,5	30
06851-01-5010X40	steel	M10	50	25	35	17,5	40
06851-01-5010X50	steel	M10	50	25	35	17,5	50
06851-01-6012X30	steel	M12	60	30	37	18,5	30
06851-01-6012X40	steel	M12	60	30	37	18,5	40
06851-01-6012X50	steel	M12	60	30	37	18,5	50

Overview of items

Order No.	Component material	D	D1	D2	H	H1	L
06851-01-13206X10	stainless steel	M6	32	16	22,5	11	10
06851-01-13206X15	stainless steel	M6	32	16	22,5	11	15
06851-01-13206X20	stainless steel	M6	32	16	22,5	11	20
06851-01-13206X35	stainless steel	M6	32	16	22,5	11	35
06851-01-13208X15	stainless steel	M8	32	16	22,5	11	15
06851-01-13208X25	stainless steel	M8	32	16	22,5	11	25
06851-01-14006X15	stainless steel	M6	40	20	28	14	15
06851-01-14008X15	stainless steel	M8	40	20	28	14	15
06851-01-14008X20	stainless steel	M8	40	20	28	14	20
06851-01-14008X25	stainless steel	M8	40	20	28	14	25
06851-01-14008X30	stainless steel	M8	40	20	28	14	30
06851-01-14008X35	stainless steel	M8	40	20	28	14	35
06851-01-14008X45	stainless steel	M8	40	20	28	14	45
06851-01-14010X30	stainless steel	M10	40	20	28	14	30
06851-01-15008X15	stainless steel	M8	50	25	35	17,5	15
06851-01-15008X25	stainless steel	M8	50	25	35	17,5	25
06851-01-15010X20	stainless steel	M10	50	25	35	17,5	20
06851-01-15010X30	stainless steel	M10	50	25	35	17,5	30
06851-01-15010X40	stainless steel	M10	50	25	35	17,5	40
06851-01-15010X50	stainless steel	M10	50	25	35	17,5	50
06851-01-16012X30	stainless steel	M12	60	30	37	18,5	30
06851-01-16012X40	stainless steel	M12	60	30	37	18,5	40
06851-01-16012X50	stainless steel	M12	60	30	37	18,5	50