

## Item description/product images

**Description****Material:**

Polyester.

**Version:**

Two layer. Fully reinforced end loops both sides, tapered to half the band width.

**Note:**

The lifting slings correspond to DIN EN 1492-1. They are made of high-strength polyester straps. The sling surface is also impregnated with polyurethane to make it abrasion-proof. The working load limit (WLL) and the cord tonnage (tonne capacity per cord) are either woven into or printed on the sling. The safety label with the CE mark and technical data is firmly sewn to the sling.

The colour of the sling corresponds to the colour code scheme for load capacities of textile type slings.

The lifting slings have high UV resistance and low moisture absorption.

Safety factor 7:1

Example: WLL 1000kg = break load 7000kg.

These lifting slings carry the CE mark according to the European machinery directive.

The stated WLL applies to a vertical lift. By a basket lift the WLL is doubled.


**Temperature range:**

-40 °C to +100 °C.

Item description/product images



Drawings

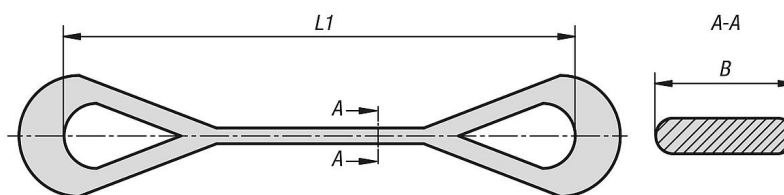

Overview of items

Order No.	Main colour	B	L1	Permissible load kg
07798-02-0100010	violet	30	1 m	1000
07798-02-0100020	violet	30	2 m	1000
07798-02-0100030	violet	30	3 m	1000
07798-02-0100040	violet	30	4 m	1000
07798-02-0100050	violet	30	5 m	1000
07798-02-0200010	green	60	1 m	2000
07798-02-0200020	green	60	2 m	2000
07798-02-0200030	green	60	3 m	2000
07798-02-0200040	green	60	4 m	2000
07798-02-0200050	green	60	5 m	2000
07798-02-0300010	yellow	90	1 m	3000
07798-02-0300020	yellow	90	2 m	3000
07798-02-0300030	yellow	90	3 m	3000
07798-02-0300040	yellow	90	4 m	3000
07798-02-0300050	yellow	90	5 m	3000
07798-02-0400010	grey	120	1 m	4000
07798-02-0400020	grey	120	2 m	4000
07798-02-0400030	grey	120	3 m	4000
07798-02-0400040	grey	120	4 m	4000
07798-02-0400050	grey	120	5 m	4000
07798-02-0500010	red	150	1 m	5000
07798-02-0500020	red	150	2 m	5000
07798-02-0500030	red	150	3 m	5000
07798-02-0500040	red	150	4 m	5000
07798-02-0500050	red	150	5 m	5000