


Item description/product images

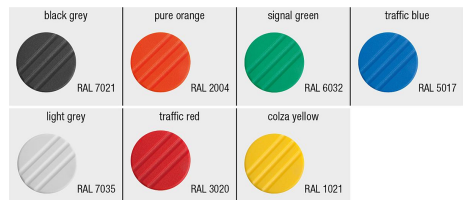

Description

Material:


Black thermoplastic.

Bush and screw 5.8 steel or 1.4305 stainless steel.

Version:

Steel trivalent blue passivated, stainless steel bright.

Drawings

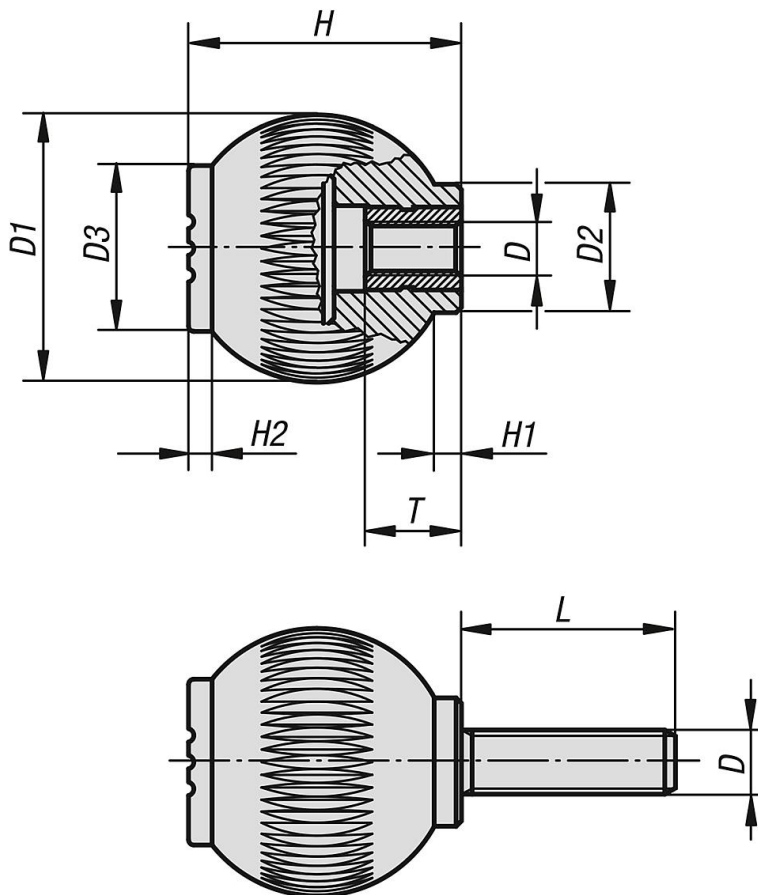

Overview of items

internal thread

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-106	internal thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	-	10
06245-1061	internal thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	-	10

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-1062	internal thread	steel	signal green RAL6032	M6	25	12	17	25	3	2	-	10
06245-1063	internal thread	steel	blue RAL5017	M6	25	12	17	25	3	2	-	10
06245-1065	internal thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	-	10
06245-1066	internal thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	-	10
06245-1067	internal thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	-	10
06245-208	internal thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	-	14
06245-2081	internal thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	-	14
06245-2082	internal thread	steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	-	14
06245-2083	internal thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	-	14
06245-2085	internal thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	-	14
06245-2086	internal thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	-	14
06245-2087	internal thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	-	14
06245-310	internal thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	-	14
06245-3101	internal thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	-	14
06245-3102	internal thread	steel	signal green RAL6032	M10	40	19	23	41	4	3	-	14
06245-3103	internal thread	steel	blue RAL5017	M10	40	19	23	41	4	3	-	14
06245-3105	internal thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	-	14
06245-3106	internal thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	-	14
06245-3107	internal thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	-	14
06245-410	internal thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	-	14
06245-4101	internal thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	-	14
06245-4102	internal thread	steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	-	14
06245-4103	internal thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	-	14
06245-4105	internal thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	-	14
06245-4106	internal thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	-	14
06245-4107	internal thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	-	14
06245-412	internal thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	-	18
06245-4121	internal thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	-	18
06245-4122	internal thread	steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	-	18
06245-4123	internal thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	-	18
06245-4125	internal thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	-	18
06245-4126	internal thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	-	18
06245-4127	internal thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	-	18
06245-0106	internal thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	-	10
06245-01061	internal thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	-	10
06245-01062	internal thread	stainless steel	signal green RAL6032	M6	25	12	17	25	3	2	-	10
06245-01063	internal thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	-	10
06245-01065	internal thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	-	10
06245-01066	internal thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	-	10
06245-01067	internal thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	-	10
06245-0208	internal thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	-	14
06245-02081	internal thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	-	14
06245-02082	internal thread	stainless steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	-	14
06245-02083	internal thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	-	14
06245-02085	internal thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	-	14
06245-02086	internal thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	-	14
06245-02087	internal thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	-	14
06245-0310	internal thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	-	14
06245-03101	internal thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	-	14
06245-03102	internal thread	stainless steel	signal green RAL6032	M10	40	19	23	41	4	3	-	14
06245-03103	internal thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	-	14
06245-03105	internal thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	-	14
06245-03106	internal thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	-	14
06245-03107	internal thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	-	14
06245-0410	internal thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	-	14
06245-04101	internal thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	-	14
06245-04102	internal thread	stainless steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	-	14
06245-04103	internal thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	-	14
06245-04105	internal thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	-	14
06245-04106	internal thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	-	14
06245-04107	internal thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	-	14
06245-0412	internal thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	-	18
06245-04121	internal thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	-	18
06245-04122	internal thread	stainless steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	-	18
06245-04123	internal thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	-	18

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-04125	internal thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	-	18
06245-04126	internal thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	-	18
06245-04127	internal thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	-	18
06245-106X15	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	15	-
06245-1061X15	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	15	-
06245-1062X15	external thread	steel	signal green RAL6032	M6	25	12	17	25	3	2	15	-
06245-1063X15	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	15	-
06245-1065X15	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	15	10
06245-1066X15	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	15	10
06245-1067X15	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	15	10
06245-106X20	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	20	-
06245-1061X20	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	20	-
06245-1062X20	external thread	steel	signal green RAL6032	M6	25	12	17	25	3	2	20	-
06245-1063X20	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	20	-
06245-1065X20	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	20	10
06245-1066X20	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	20	10
06245-1067X20	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	20	10
06245-106X25	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	25	-
06245-1061X25	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	25	-
06245-1062X25	external thread	steel	signal green RAL6032	M6	25	12	17	25	3	2	25	-
06245-1063X25	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	25	-
06245-1065X25	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	25	10
06245-1066X25	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	25	10
06245-1067X25	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	25	10
06245-106X30	external thread	steel	black grey RAL 7021	M6	25	12	17	25	3	2	30	-
06245-1061X30	external thread	steel	orange RAL 2004	M6	25	12	17	25	3	2	30	-
06245-1062X30	external thread	steel	signal green RAL6032	M6	25	12	17	25	3	2	30	-
06245-1063X30	external thread	steel	blue RAL5017	M6	25	12	17	25	3	2	30	-
06245-1065X30	external thread	steel	light grey RAL 7035	M6	25	12	17	25	3	2	30	10
06245-1066X30	external thread	steel	traffic red RAL 3020	M6	25	12	17	25	3	2	30	10
06245-1067X30	external thread	steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	30	10
06245-208X20	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	20	-
06245-2081X20	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	20	-
06245-2082X20	external thread	steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	20	-
06245-2083X20	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	20	-
06245-2085X20	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	20	-
06245-2086X20	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	20	-
06245-2087X20	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	20	-
06245-208X25	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	25	-
06245-2081X25	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	25	-
06245-2082X25	external thread	steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	25	-
06245-2083X25	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	25	-
06245-2085X25	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	25	-
06245-2086X25	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	25	-
06245-2087X25	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	25	-
06245-208X30	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	30	-
06245-2081X30	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	30	-
06245-2082X30	external thread	steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	30	-
06245-2083X30	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	30	-
06245-2085X30	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	30	-
06245-2086X30	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	30	-
06245-2087X30	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	30	-
06245-208X40	external thread	steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	40	-
06245-2081X40	external thread	steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	40	-
06245-2082X40	external thread	steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	40	-
06245-2083X40	external thread	steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	40	-
06245-2085X40	external thread	steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	40	-
06245-2086X40	external thread	steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	40	-
06245-2087X40	external thread	steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	40	-
06245-310X20	external thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	20	-
06245-3101X20	external thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	20	-
06245-3102X20	external thread	steel	signal green RAL6032	M10	40	19	23	41	4	3	20	-
06245-3103X20	external thread	steel	blue RAL5017	M10	40	19	23	41	4	3	20	-
06245-3105X20	external thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	20	14
06245-3106X20	external thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	20	14

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-3107X20	external thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	20	14
06245-310X30	external thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	30	-
06245-3101X30	external thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	30	-
06245-3102X30	external thread	steel	signal green RAL6032	M10	40	19	23	41	4	3	30	-
06245-3103X30	external thread	steel	blue RAL5017	M10	40	19	23	41	4	3	30	-
06245-3105X30	external thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	30	14
06245-3106X30	external thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	30	14
06245-3107X30	external thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	30	14
06245-310X40	external thread	steel	black grey RAL 7021	M10	40	19	23	41	4	3	40	-
06245-3101X40	external thread	steel	orange RAL 2004	M10	40	19	23	41	4	3	40	-
06245-3102X40	external thread	steel	signal green RAL6032	M10	40	19	23	41	4	3	40	-
06245-3103X40	external thread	steel	blue RAL5017	M10	40	19	23	41	4	3	40	-
06245-3105X40	external thread	steel	light grey RAL 7035	M10	40	19	23	41	4	3	40	14
06245-3106X40	external thread	steel	traffic red RAL 3020	M10	40	19	23	41	4	3	40	14
06245-3107X40	external thread	steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	40	14
06245-410X20	external thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	20	-
06245-4101X20	external thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	20	-
06245-4102X20	external thread	steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	20	-
06245-4103X20	external thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	20	-
06245-4105X20	external thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	20	14
06245-4106X20	external thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	20	14
06245-4107X20	external thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	20	14
06245-410X30	external thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	30	-
06245-4101X30	external thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	30	-
06245-4102X30	external thread	steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	30	-
06245-4103X30	external thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	30	-
06245-4105X30	external thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	30	14
06245-4106X30	external thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	30	14
06245-4107X30	external thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	30	14
06245-410X40	external thread	steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	40	-
06245-4101X40	external thread	steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	40	-
06245-4102X40	external thread	steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	40	-
06245-4103X40	external thread	steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	40	-
06245-4105X40	external thread	steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	40	14
06245-4106X40	external thread	steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	40	14
06245-4107X40	external thread	steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	40	14
06245-412X20	external thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	20	-
06245-4121X20	external thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	20	-
06245-4122X20	external thread	steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	20	-
06245-4123X20	external thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	20	-
06245-4125X20	external thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	20	18
06245-4126X20	external thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	20	18
06245-4127X20	external thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	20	18
06245-412X30	external thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	30	-
06245-4121X30	external thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	30	-
06245-4122X30	external thread	steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	30	-
06245-4123X30	external thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	30	-
06245-4125X30	external thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	30	18
06245-4126X30	external thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	30	18
06245-4127X30	external thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	30	18
06245-412X40	external thread	steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	40	-
06245-4121X40	external thread	steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	40	-
06245-4122X40	external thread	steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	40	-
06245-4123X40	external thread	steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	40	-
06245-4125X40	external thread	steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	40	18
06245-4126X40	external thread	steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	40	18
06245-4127X40	external thread	steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	40	18
06245-0106X15	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	15	-
06245-01061X15	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	15	-
06245-01062X15	external thread	stainless steel	signal green RAL6032	M6	25	12	17	25	3	2	15	-
06245-01063X15	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	15	-
06245-01065X15	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	15	10
06245-01066X15	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	15	10
06245-01067X15	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	15	10
06245-0106X20	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	20	-

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-01061X20	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	20	-
06245-01062X20	external thread	stainless steel	signal green RAL6032	M6	25	12	17	25	3	2	20	-
06245-01063X20	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	20	-
06245-01065X20	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	20	10
06245-01066X20	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	20	10
06245-01067X20	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	20	10
06245-0106X25	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	25	-
06245-01061X25	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	25	-
06245-01062X25	external thread	stainless steel	signal green RAL6032	M6	25	12	17	25	3	2	25	-
06245-01063X25	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	25	-
06245-01065X25	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	25	10
06245-01066X25	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	25	10
06245-01067X25	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	25	10
06245-0106X30	external thread	stainless steel	black grey RAL 7021	M6	25	12	17	25	3	2	30	-
06245-01061X30	external thread	stainless steel	orange RAL 2004	M6	25	12	17	25	3	2	30	-
06245-01062X30	external thread	stainless steel	signal green RAL6032	M6	25	12	17	25	3	2	30	-
06245-01063X30	external thread	stainless steel	blue RAL5017	M6	25	12	17	25	3	2	30	-
06245-01065X30	external thread	stainless steel	light grey RAL 7035	M6	25	12	17	25	3	2	30	10
06245-01066X30	external thread	stainless steel	traffic red RAL 3020	M6	25	12	17	25	3	2	30	10
06245-01067X30	external thread	stainless steel	colza yellow RAL 1021	M6	25	12	17	25	3	2	30	10
06245-0208X20	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	20	-
06245-02081X20	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	20	-
06245-02082X20	external thread	stainless steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	20	-
06245-02083X20	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	20	-
06245-02085X20	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	20	-
06245-02086X20	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	20	-
06245-02087X20	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	20	-
06245-0208X25	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	25	-
06245-02081X25	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	25	-
06245-02082X25	external thread	stainless steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	25	-
06245-02083X25	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	25	-
06245-02085X25	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	25	-
06245-02086X25	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	25	-
06245-02087X25	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	25	-
06245-0208X30	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	30	-
06245-02081X30	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	30	-
06245-02082X30	external thread	stainless steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	30	-
06245-02083X30	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	30	-
06245-02085X30	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	30	-
06245-02086X30	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	30	-
06245-02087X30	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	30	-
06245-0208X40	external thread	stainless steel	black grey RAL 7021	M8	32	15,5	19	33	3,5	2,6	40	-
06245-02081X40	external thread	stainless steel	orange RAL 2004	M8	32	15,5	19	33	3,5	2,6	40	-
06245-02082X40	external thread	stainless steel	signal green RAL6032	M8	32	15,5	19	33	3,5	2,6	40	-
06245-02083X40	external thread	stainless steel	blue RAL5017	M8	32	15,5	19	33	3,5	2,6	40	-
06245-02085X40	external thread	stainless steel	light grey RAL 7035	M8	32	15,5	19	33	3,5	2,6	40	-
06245-02086X40	external thread	stainless steel	traffic red RAL 3020	M8	32	15,5	19	33	3,5	2,6	40	-
06245-02087X40	external thread	stainless steel	colza yellow RAL 1021	M8	32	15,5	19	33	3,5	2,6	40	-
06245-0310X20	external thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	20	-
06245-03101X20	external thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	20	-
06245-03102X20	external thread	stainless steel	signal green RAL6032	M10	40	19	23	41	4	3	20	-
06245-03103X20	external thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	20	-
06245-03105X20	external thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	20	14
06245-03106X20	external thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	20	14
06245-03107X20	external thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	20	14
06245-0310X30	external thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	30	-
06245-03101X30	external thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	30	-
06245-03102X30	external thread	stainless steel	signal green RAL6032	M10	40	19	23	41	4	3	30	-
06245-03103X30	external thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	30	-
06245-03105X30	external thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	30	14
06245-03106X30	external thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	30	14
06245-03107X30	external thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	30	14
06245-0310X40	external thread	stainless steel	black grey RAL 7021	M10	40	19	23	41	4	3	40	-
06245-03101X40	external thread	stainless steel	orange RAL 2004	M10	40	19	23	41	4	3	40	-
06245-03102X40	external thread	stainless steel	signal green RAL6032	M10	40	19	23	41	4	3	40	-

Overview of items

Order No.	Thread type	Component material	Colour Cap	D	D1	D2	D3	H	H1	H2	L	T
06245-03103X40	external thread	stainless steel	blue RAL5017	M10	40	19	23	41	4	3	40	-
06245-03105X40	external thread	stainless steel	light grey RAL 7035	M10	40	19	23	41	4	3	40	14
06245-03106X40	external thread	stainless steel	traffic red RAL 3020	M10	40	19	23	41	4	3	40	14
06245-03107X40	external thread	stainless steel	colza yellow RAL 1021	M10	40	19	23	41	4	3	40	14
06245-0410X20	external thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	20	-
06245-04101X20	external thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	20	-
06245-04102X20	external thread	stainless steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	20	-
06245-04103X20	external thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	20	-
06245-04105X20	external thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	20	14
06245-04106X20	external thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	20	14
06245-04107X20	external thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	20	14
06245-0410X30	external thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	30	-
06245-04101X30	external thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	30	-
06245-04102X30	external thread	stainless steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	30	-
06245-04103X30	external thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	30	-
06245-04105X30	external thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	30	14
06245-04106X30	external thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	30	14
06245-04107X30	external thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	30	14
06245-0410X40	external thread	stainless steel	black grey RAL 7021	M10	50	24	31	51	5,5	4,5	40	-
06245-04101X40	external thread	stainless steel	orange RAL 2004	M10	50	24	31	51	5,5	4,5	40	-
06245-04102X40	external thread	stainless steel	signal green RAL6032	M10	50	24	31	51	5,5	4,5	40	-
06245-04103X40	external thread	stainless steel	blue RAL5017	M10	50	24	31	51	5,5	4,5	40	-
06245-04105X40	external thread	stainless steel	light grey RAL 7035	M10	50	24	31	51	5,5	4,5	40	14
06245-04106X40	external thread	stainless steel	traffic red RAL 3020	M10	50	24	31	51	5,5	4,5	40	14
06245-04107X40	external thread	stainless steel	colza yellow RAL 1021	M10	50	24	31	51	5,5	4,5	40	14
06245-0412X20	external thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	20	-
06245-04121X20	external thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	20	-
06245-04122X20	external thread	stainless steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	20	-
06245-04123X20	external thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	20	-
06245-04125X20	external thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	20	18
06245-04126X20	external thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	20	18
06245-04127X20	external thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	20	18
06245-0412X30	external thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	30	-
06245-04121X30	external thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	30	-
06245-04122X30	external thread	stainless steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	30	-
06245-04123X30	external thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	30	-
06245-04125X30	external thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	30	18
06245-04126X30	external thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	30	18
06245-04127X30	external thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	30	18
06245-0412X40	external thread	stainless steel	black grey RAL 7021	M12	50	24	31	51	5,5	4,5	40	-
06245-04121X40	external thread	stainless steel	orange RAL 2004	M12	50	24	31	51	5,5	4,5	40	-
06245-04122X40	external thread	stainless steel	signal green RAL6032	M12	50	24	31	51	5,5	4,5	40	-
06245-04123X40	external thread	stainless steel	blue RAL5017	M12	50	24	31	51	5,5	4,5	40	-
06245-04125X40	external thread	stainless steel	light grey RAL 7035	M12	50	24	31	51	5,5	4,5	40	18
06245-04126X40	external thread	stainless steel	traffic red RAL 3020	M12	50	24	31	51	5,5	4,5	40	18
06245-04127X40	external thread	stainless steel	colza yellow RAL 1021	M12	50	24	31	51	5,5	4,5	40	18