


Item description/product images

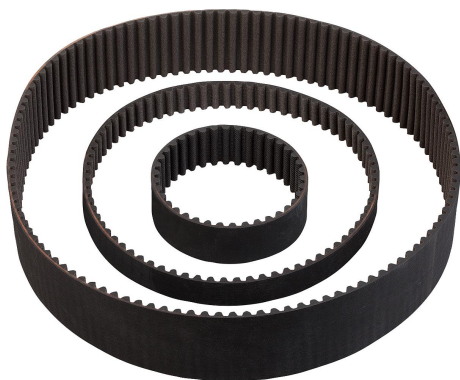

Description

Material:

Belt back and belt teeth CR.
Tension cords Glascord.
Tooth covering mesh polyamide.

Note:

Endless toothed belts with an arched profile as per ISO 13050 with metric pitch.
The rounded shape of the tooth contour provides a particularly high degree of safety against incorrect tooth interlocking, combined with a very rounded tooth mesh.
Operating noise is significantly reduced by the rounded tooth mesh.
The toothed belts are robust, economical and versatile.


Temperature range:

From -20°C to +100°C

Features:

- Belt speed v_{max} perm. 50 m/s
- Transmissible power up to 99.1 kW
- Permissible speed up to 6000 rpm
- Low-noise and low-maintenance
- Very good chemical resistance, particularly against oils, greases and fuels
- Accurate positioning and angles

Drawings

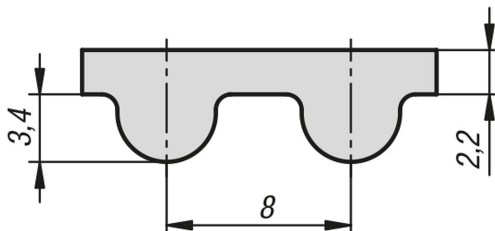

Overview of items

Order No.	belt width	No. of teeth	Effective length
22062-0820X0288	20	36	288
22062-0820X0304	20	38	304
22062-0820X0352	20	44	352
22062-0820X0376	20	47	376
22062-0820X0400	20	50	400
22062-0820X0416	20	52	416
22062-0820X0424	20	53	424
22062-0820X0480	20	60	480
22062-0820X0560	20	70	560
22062-0820X0600	20	75	600
22062-0820X0640	20	80	640
22062-0820X0656	20	82	656
22062-0820X0688	20	86	688
22062-0820X0720	20	90	720
22062-0820X0784	20	98	784
22062-0820X0800	20	100	800
22062-0820X0880	20	110	880
22062-0820X0920	20	115	920
22062-0820X0960	20	120	960

Overview of items

Order No.	belt width	No. of teeth	Effective length
22062-0820X1040	20	130	1040
22062-0820X1120	20	140	1120
22062-0820X1160	20	145	1160
22062-0820X1200	20	150	1200
22062-0820X1280	20	160	1280
22062-0820X1304	20	163	1304
22062-0820X1360	20	170	1360
22062-0820X1424	20	178	1424
22062-0820X1440	20	180	1440
22062-0820X1520	20	190	1520
22062-0820X1600	20	200	1600
22062-0820X1760	20	220	1760
22062-0820X1800	20	225	1800
22062-0820X2000	20	250	2000
22062-0820X2248	20	281	2248
22062-0820X2400	20	300	2400
22062-0820X2600	20	325	2600
22062-0820X2800	20	350	2800
22062-0820X3008	20	376	3008
22062-0820X3280	20	410	3280
22062-0820X3408	20	426	3408
22062-0820X3808	20	476	3808
22062-0830X0288	30	36	288
22062-0830X0304	30	38	304
22062-0830X0352	30	44	352
22062-0830X0376	30	47	376
22062-0830X0400	30	50	400
22062-0830X0416	30	52	416
22062-0830X0424	30	53	424
22062-0830X0480	30	60	480
22062-0830X0560	30	70	560
22062-0830X0600	30	75	600
22062-0830X0640	30	80	640
22062-0830X0656	30	82	656
22062-0830X0688	30	86	688
22062-0830X0720	30	90	720
22062-0830X0784	30	98	784
22062-0830X0800	30	100	800
22062-0830X0880	30	110	880
22062-0830X0920	30	115	920
22062-0830X0960	30	120	960
22062-0830X1040	30	130	1040
22062-0830X1120	30	140	1120
22062-0830X1160	30	145	1160
22062-0830X1200	30	150	1200
22062-0830X1280	30	160	1280
22062-0830X1304	30	163	1304
22062-0830X1360	30	170	1360
22062-0830X1424	30	178	1424
22062-0830X1440	30	180	1440
22062-0830X1520	30	190	1520
22062-0830X1600	30	200	1600
22062-0830X1760	30	220	1760
22062-0830X1800	30	225	1800
22062-0830X2000	30	250	2000
22062-0830X2248	30	281	2248
22062-0830X2400	30	300	2400
22062-0830X2600	30	325	2600
22062-0830X2800	30	350	2800
22062-0830X3008	30	376	3008
22062-0830X3280	30	410	3280
22062-0830X3408	30	426	3408
22062-0830X3808	30	476	3808
22062-0850X0288	50	36	288
22062-0850X0304	50	38	304

Overview of items

Order No.	belt width	No. of teeth	Effective length
22062-0850X0352	50	44	352
22062-0850X0376	50	47	376
22062-0850X0400	50	50	400
22062-0850X0416	50	52	416
22062-0850X0424	50	53	424
22062-0850X0480	50	60	480
22062-0850X0560	50	70	560
22062-0850X0600	50	75	600
22062-0850X0640	50	80	640
22062-0850X0656	50	82	656
22062-0850X0688	50	86	688
22062-0850X0720	50	90	720
22062-0850X0784	50	98	784
22062-0850X0800	50	100	800
22062-0850X0880	50	110	880
22062-0850X0920	50	115	920
22062-0850X0960	50	120	960
22062-0850X1040	50	130	1040
22062-0850X1120	50	140	1120
22062-0850X1160	50	145	1160
22062-0850X1200	50	150	1200
22062-0850X1280	50	160	1280
22062-0850X1304	50	163	1304
22062-0850X1360	50	170	1360
22062-0850X1424	50	178	1424
22062-0850X1440	50	180	1440
22062-0850X1520	50	190	1520
22062-0850X1600	50	200	1600
22062-0850X1760	50	220	1760
22062-0850X1800	50	225	1800
22062-0850X2000	50	250	2000
22062-0850X2248	50	281	2248
22062-0850X2400	50	300	2400
22062-0850X2600	50	325	2600
22062-0850X2800	50	350	2800
22062-0850X3008	50	376	3008
22062-0850X3280	50	410	3280
22062-0850X3408	50	426	3408
22062-0850X3808	50	476	3808