

Item description/product images



Description

Material:

Steel.

Version:

Powder-coated black RAL 9005, red RAL 3000 or trivalent blue passivated.


Note:

Especially suitable for stop valves. The handwheels are made from a single piece. The handwheel is strengthened in the hub area using a special forming process. The tapered hub allows easy mounting and ensures secure seating on the square bar.

Drawing reference:

1) Square on shaft

Drawings

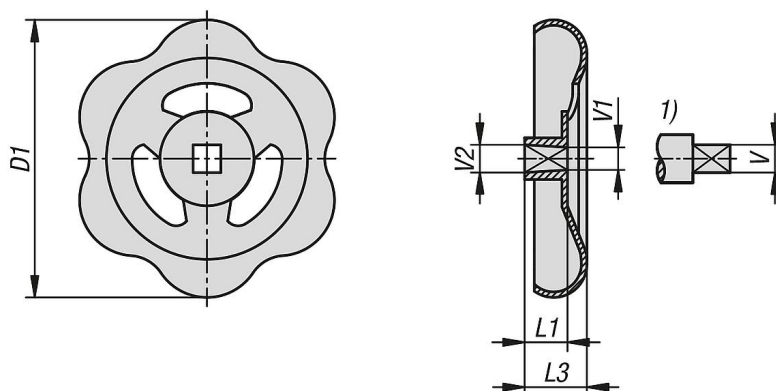

Overview of items

Hand wheels, steel, stamped

Order No.	Main colour	Surface finish body	D1	L1	L3	V	V1	V2	Number of spokes
06289-050060	jet black RAL 9005	-	50	8,5	12	6	5,9	6,15	3
06289-050070	jet black RAL 9005	-	50	8,5	12	7	6,9	7,15	3
06289-060060	jet black RAL 9005	-	60	8,5	12	6	5,9	6,15	3
06289-060070	jet black RAL 9005	-	60	8,5	12	7	6,9	7,15	3
06289-070070	jet black RAL 9005	-	69	10	15	7	6,9	7,15	3
06289-070080	jet black RAL 9005	-	69	10	15	8	7,9	8,15	3
06289-080080	jet black RAL 9005	-	78	11	16	8	7,9	8,15	3
06289-080090	jet black RAL 9005	-	78	11	16	9	8,9	9,15	3
06289-090090	jet black RAL 9005	-	89	11	16	9	8,9	9,15	3
06289-100090	jet black RAL 9005	-	98	13	20	9	8,9	9,15	3
06289-100100	jet black RAL 9005	-	98	13	20	10	9,9	10,15	3
06289-110100	jet black RAL 9005	-	108	15	23	10	9,9	10,15	3
06289-130120	jet black RAL 9005	-	130	15	23	12	11,9	12,15	3
06289-050061	red RAL 3000	-	50	8,5	12	6	5,9	6,15	3
06289-050071	red RAL 3000	-	50	8,5	12	7	6,9	7,15	3
06289-060061	red RAL 3000	-	60	8,5	12	6	5,9	6,15	3
06289-060071	red RAL 3000	-	60	8,5	12	7	6,9	7,15	3
06289-070071	red RAL 3000	-	69	10	15	7	6,9	7,15	3
06289-070081	red RAL 3000	-	69	10	15	8	7,9	8,15	3
06289-080081	red RAL 3000	-	78	11	16	8	7,9	8,15	3
06289-080091	red RAL 3000	-	78	11	16	9	8,9	9,15	3

Overview of items

Order No.	Main colour	Surface finish body	D1	L1	L3	V	V1	V2	Number of spokes
06289-090091	red RAL 3000	-	89	11	16	9	8,9	9,15	3
06289-100091	red RAL 3000	-	98	13	20	9	8,9	9,15	3
06289-100101	red RAL 3000	-	98	13	20	10	9,9	10,15	3
06289-110101	red RAL 3000	-	108	15	23	10	9,9	10,15	3
06289-130121	red RAL 3000	-	130	15	23	12	11,9	12,15	3
06289-050062	-	galvanised	50	8,5	12	6	5,9	6,15	3
06289-050072	-	galvanised	50	8,5	12	7	6,9	7,15	3
06289-060062	-	galvanised	60	8,5	12	6	5,9	6,15	3
06289-060072	-	galvanised	60	8,5	12	7	6,9	7,15	3
06289-070072	-	galvanised	69	10	15	7	6,9	7,15	3
06289-070082	-	galvanised	69	10	15	8	7,9	8,15	3
06289-080082	-	galvanised	78	11	16	8	7,9	8,15	3
06289-080092	-	galvanised	78	11	16	9	8,9	9,15	3
06289-090092	-	galvanised	89	11	16	9	8,9	9,15	3
06289-100092	-	galvanised	98	13	20	9	8,9	9,15	3
06289-100102	-	galvanised	98	13	20	10	9,9	10,15	3
06289-110102	-	galvanised	108	15	23	10	9,9	10,15	3
06289-130122	-	galvanised	130	15	23	12	11,9	12,15	3