

Item description/product images

**Description****Material:**

Foot plate and threaded spindle steel or stainless steel 1.4301.
Rubber support (NBR) 80 Shore.

Version:

Foot plate and threaded spindle electro zinc-plated steel.
Foot plate polished stainless steel.
Threaded spindle bright stainless steel.
Rubber support, vulcanised, black.

Note:


Levelling feet steel or stainless steel with pivoting threaded spindle and rubber base. The solid rubber base is permanently vulcanised to the sheet metal plate. The rubber base has an excellent surface grip. It is sound damping and impedes transmission of vibrations and impacts to the floor.

The load values specified in the table are based on a test series, in which a static load was applied perpendicular to the plates through the centre of the spindle. Radially acting forces such as those produced by vibrations or other shaking effects, affect the load rating and are not taken into account for the specified values.

For stainless steel feet from spindle size M16, the wrench sizes apply across two flats.

Supplied with matching nut.

Drawings

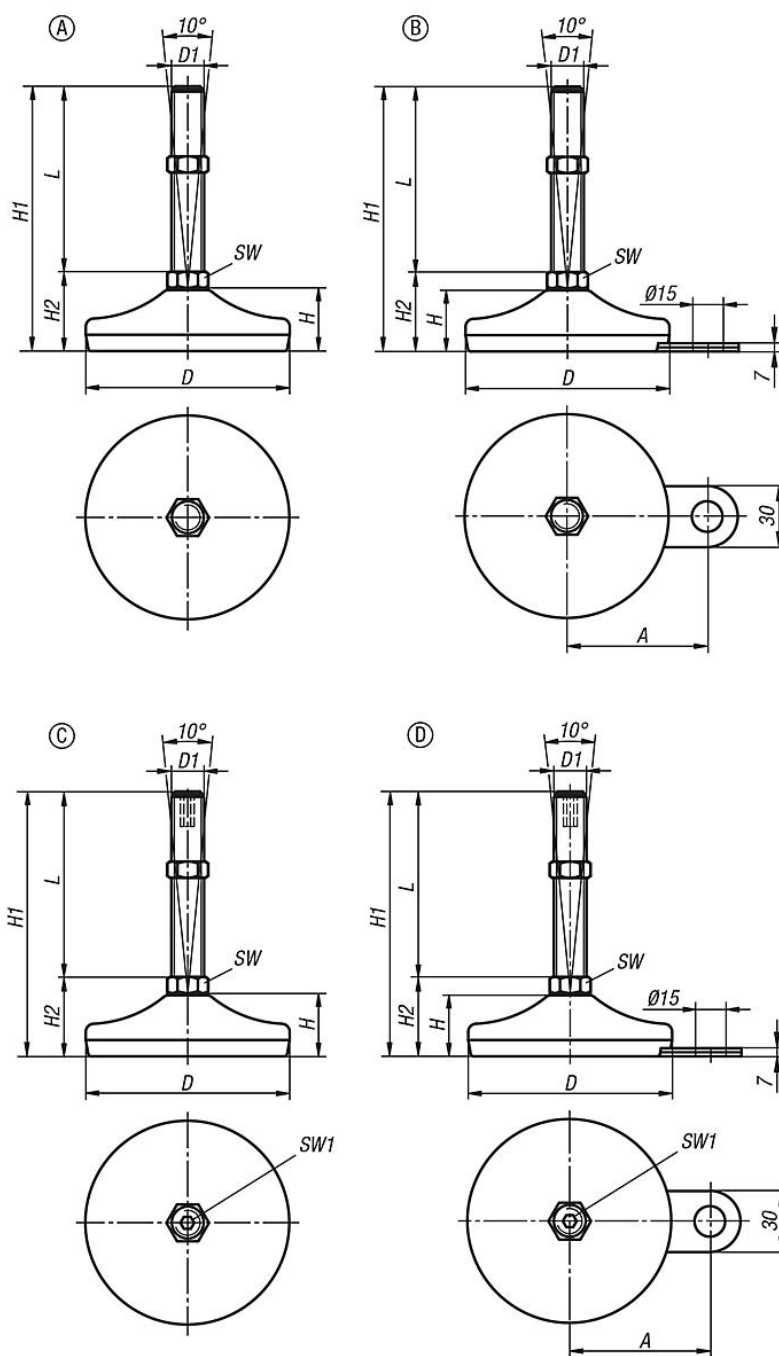

Overview of items

| Order No. | Form | Main material | A | D | D1 | H | H1 | H2 | L | SW | SW1 | Load rating max. kN (static load only) |
|-------------------|------|---------------|---|----|-----|----|-----|----|-----|----|-----|--|
| 27790-1105010X50 | A | steel | - | 50 | M10 | 19 | 79 | 29 | 50 | 14 | - | 4 |
| 27790-1105010X100 | A | steel | - | 50 | M10 | 19 | 129 | 29 | 100 | 14 | - | 4 |
| 27790-1105012X50 | A | steel | - | 50 | M12 | 19 | 79 | 29 | 50 | 14 | - | 4 |
| 27790-1105012X100 | A | steel | - | 50 | M12 | 19 | 129 | 29 | 100 | 14 | - | 4 |
| 27790-1105012X150 | A | steel | - | 50 | M12 | 19 | 179 | 29 | 150 | 14 | - | 4 |
| 27790-1106010X50 | A | steel | - | 60 | M10 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-1106010X100 | A | steel | - | 60 | M10 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-1106012X50 | A | steel | - | 60 | M12 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-1106012X100 | A | steel | - | 60 | M12 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-1106012X150 | A | steel | - | 60 | M12 | 22 | 182 | 32 | 150 | 14 | - | 7 |

Overview of items

| Order No. | Form | Main material | A | D | D1 | H | H1 | H2 | L | SW | SW1 | Load rating max. kN (static load only) |
|-------------------|------|-----------------|---|-----|-----|----|-------|------|-----|----|-----|--|
| 27790-1108010X50 | A | steel | - | 80 | M10 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-1108010X100 | A | steel | - | 80 | M10 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-1108012X50 | A | steel | - | 80 | M12 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-1108012X100 | A | steel | - | 80 | M12 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-1108012X150 | A | steel | - | 80 | M12 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-1108014X50 | A | steel | - | 80 | M14 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-1108014X100 | A | steel | - | 80 | M14 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-1108014X150 | A | steel | - | 80 | M14 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-1108016X100 | A | steel | - | 80 | M16 | 25 | 135 | 35 | 100 | 16 | - | 10 |
| 27790-1108016X150 | A | steel | - | 80 | M16 | 25 | 185 | 35 | 150 | 16 | - | 10 |
| 27790-1108020X75 | A | steel | - | 80 | M20 | 25 | 111 | 36 | 75 | 20 | - | 10 |
| 27790-1108020X100 | A | steel | - | 80 | M20 | 25 | 136 | 36 | 100 | 20 | - | 10 |
| 27790-1108020X150 | A | steel | - | 80 | M20 | 25 | 186 | 36 | 150 | 20 | - | 10 |
| 27790-1108020X200 | A | steel | - | 80 | M20 | 25 | 236 | 36 | 200 | 20 | - | 10 |
| 27790-1110020X75 | A | steel | - | 100 | M20 | 28 | 113,5 | 38,5 | 75 | 20 | - | 15 |
| 27790-1110020X100 | A | steel | - | 100 | M20 | 28 | 138,5 | 38,5 | 100 | 20 | - | 15 |
| 27790-1110020X150 | A | steel | - | 100 | M20 | 28 | 188,5 | 38,5 | 150 | 20 | - | 15 |
| 27790-1110020X200 | A | steel | - | 100 | M20 | 28 | 238,5 | 38,5 | 200 | 20 | - | 15 |
| 27790-1110020X250 | A | steel | - | 100 | M20 | 28 | 288,5 | 38,5 | 250 | 20 | - | 15 |
| 27790-1110024X100 | A | steel | - | 100 | M24 | 28 | 138,5 | 38,5 | 100 | 24 | - | 15 |
| 27790-1110024X150 | A | steel | - | 100 | M24 | 28 | 188,5 | 38,5 | 150 | 24 | - | 15 |
| 27790-1110024X200 | A | steel | - | 100 | M24 | 28 | 238,5 | 38,5 | 200 | 24 | - | 15 |
| 27790-1110024X250 | A | steel | - | 100 | M24 | 28 | 288,5 | 38,5 | 250 | 24 | - | 15 |
| 27790-1112020X100 | A | steel | - | 120 | M20 | 32 | 142,5 | 42,5 | 100 | 20 | - | 30 |
| 27790-1112020X150 | A | steel | - | 120 | M20 | 32 | 192,5 | 42,5 | 150 | 20 | - | 30 |
| 27790-1112020X200 | A | steel | - | 120 | M20 | 32 | 242,5 | 42,5 | 200 | 20 | - | 30 |
| 27790-1112024X100 | A | steel | - | 120 | M24 | 32 | 142,5 | 42,5 | 100 | 24 | - | 30 |
| 27790-1112024X150 | A | steel | - | 120 | M24 | 32 | 192,5 | 42,5 | 150 | 24 | - | 30 |
| 27790-1112024X200 | A | steel | - | 120 | M24 | 32 | 242,5 | 42,5 | 200 | 24 | - | 30 |
| 27790-1112030X100 | A | steel | - | 120 | M30 | 32 | 143,5 | 43,5 | 100 | 30 | - | 30 |
| 27790-1112030X150 | A | steel | - | 120 | M30 | 32 | 193,5 | 43,5 | 150 | 30 | - | 30 |
| 27790-1112030X200 | A | steel | - | 120 | M30 | 32 | 243,5 | 43,5 | 200 | 30 | - | 30 |
| 27790-1205010X50 | A | stainless steel | - | 50 | M10 | 19 | 79 | 29 | 50 | 14 | - | 4 |
| 27790-1205010X100 | A | stainless steel | - | 50 | M10 | 19 | 129 | 29 | 100 | 14 | - | 4 |
| 27790-1205012X50 | A | stainless steel | - | 50 | M12 | 19 | 79 | 29 | 50 | 14 | - | 4 |
| 27790-1205012X100 | A | stainless steel | - | 50 | M12 | 19 | 129 | 29 | 100 | 14 | - | 4 |
| 27790-1205012X150 | A | stainless steel | - | 50 | M12 | 19 | 179 | 29 | 150 | 14 | - | 4 |
| 27790-1206010X50 | A | stainless steel | - | 60 | M10 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-1206010X100 | A | stainless steel | - | 60 | M10 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-1206012X50 | A | stainless steel | - | 60 | M12 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-1206012X100 | A | stainless steel | - | 60 | M12 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-1206012X150 | A | stainless steel | - | 60 | M12 | 22 | 182 | 32 | 150 | 14 | - | 7 |
| 27790-1208010X50 | A | stainless steel | - | 80 | M10 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-1208010X75 | A | stainless steel | - | 80 | M10 | 25 | 110 | 35 | 75 | 14 | - | 10 |
| 27790-1208010X100 | A | stainless steel | - | 80 | M10 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-1208010X125 | A | stainless steel | - | 80 | M10 | 25 | 160 | 35 | 125 | 14 | - | 10 |
| 27790-1208012X50 | A | stainless steel | - | 80 | M12 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-1208012X75 | A | stainless steel | - | 80 | M12 | 25 | 110 | 35 | 75 | 14 | - | 10 |
| 27790-1208012X100 | A | stainless steel | - | 80 | M12 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-1208012X125 | A | stainless steel | - | 80 | M12 | 25 | 160 | 35 | 125 | 14 | - | 10 |
| 27790-1208012X150 | A | stainless steel | - | 80 | M12 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-1208014X75 | A | stainless steel | - | 80 | M14 | 25 | 110 | 35 | 75 | 14 | - | 10 |
| 27790-1208014X100 | A | stainless steel | - | 80 | M14 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-1208014X125 | A | stainless steel | - | 80 | M14 | 25 | 160 | 35 | 125 | 14 | - | 10 |
| 27790-1208014X150 | A | stainless steel | - | 80 | M14 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-1208014X175 | A | stainless steel | - | 80 | M14 | 25 | 210 | 35 | 175 | 14 | - | 10 |
| 27790-1208016X75 | A | stainless steel | - | 80 | M16 | 25 | 110 | 35 | 75 | 13 | - | 10 |
| 27790-1208016X100 | A | stainless steel | - | 80 | M16 | 25 | 135 | 35 | 100 | 13 | - | 10 |
| 27790-1208016X125 | A | stainless steel | - | 80 | M16 | 25 | 160 | 35 | 125 | 13 | - | 10 |
| 27790-1208016X150 | A | stainless steel | - | 80 | M16 | 25 | 185 | 35 | 150 | 13 | - | 10 |
| 27790-1208016X175 | A | stainless steel | - | 80 | M16 | 25 | 210 | 35 | 175 | 13 | - | 10 |
| 27790-1208020X75 | A | stainless steel | - | 80 | M20 | 25 | 113 | 38 | 75 | 17 | - | 10 |
| 27790-1208020X100 | A | stainless steel | - | 80 | M20 | 25 | 138 | 38 | 100 | 17 | - | 10 |
| 27790-1208020X125 | A | stainless steel | - | 80 | M20 | 25 | 163 | 38 | 125 | 17 | - | 10 |

Overview of items

| Order No. | Form | Main material | A | D | D1 | H | H1 | H2 | L | SW | SW1 | Load rating max. kN (static load only) |
|-------------------|------|-----------------|----|-----|-----|----|-------|------|-----|----|-----|--|
| 27790-1208020X150 | A | stainless steel | - | 80 | M20 | 25 | 188 | 38 | 150 | 17 | - | 10 |
| 27790-1208020X175 | A | stainless steel | - | 80 | M20 | 25 | 213 | 38 | 175 | 17 | - | 10 |
| 27790-1208020X200 | A | stainless steel | - | 80 | M20 | 25 | 238 | 38 | 200 | 17 | - | 10 |
| 27790-1208020X225 | A | stainless steel | - | 80 | M20 | 25 | 263 | 38 | 225 | 17 | - | 10 |
| 27790-1210020X75 | A | stainless steel | - | 100 | M20 | 30 | 118 | 43 | 75 | 17 | - | 15 |
| 27790-1210020X100 | A | stainless steel | - | 100 | M20 | 30 | 143 | 43 | 100 | 17 | - | 15 |
| 27790-1210020X125 | A | stainless steel | - | 100 | M20 | 30 | 168 | 43 | 125 | 17 | - | 15 |
| 27790-1210020X150 | A | stainless steel | - | 100 | M20 | 30 | 193 | 43 | 150 | 17 | - | 15 |
| 27790-1210020X175 | A | stainless steel | - | 100 | M20 | 30 | 218 | 43 | 175 | 17 | - | 15 |
| 27790-1210020X200 | A | stainless steel | - | 100 | M20 | 30 | 243 | 43 | 200 | 17 | - | 15 |
| 27790-1210024X100 | A | stainless steel | - | 100 | M24 | 30 | 144 | 44 | 100 | 20 | - | 15 |
| 27790-1210024X125 | A | stainless steel | - | 100 | M24 | 30 | 169 | 44 | 125 | 20 | - | 15 |
| 27790-1210024X150 | A | stainless steel | - | 100 | M24 | 30 | 194 | 44 | 150 | 20 | - | 15 |
| 27790-1210024X175 | A | stainless steel | - | 100 | M24 | 30 | 219 | 44 | 175 | 20 | - | 15 |
| 27790-1210024X200 | A | stainless steel | - | 100 | M24 | 30 | 244 | 44 | 200 | 20 | - | 15 |
| 27790-1212020X100 | A | stainless steel | - | 120 | M20 | 32 | 143 | 43 | 100 | 17 | - | 30 |
| 27790-1212020X150 | A | stainless steel | - | 120 | M20 | 32 | 192 | 42 | 150 | 17 | - | 30 |
| 27790-1212020X200 | A | stainless steel | - | 120 | M20 | 32 | 242 | 42 | 200 | 17 | - | 30 |
| 27790-1212024X100 | A | stainless steel | - | 120 | M24 | 32 | 144 | 44 | 100 | 20 | - | 30 |
| 27790-1212024X150 | A | stainless steel | - | 120 | M24 | 32 | 194 | 44 | 150 | 20 | - | 30 |
| 27790-1212024X200 | A | stainless steel | - | 120 | M24 | 32 | 244 | 44 | 200 | 20 | - | 30 |
| 27790-1212030X100 | A | stainless steel | - | 120 | M30 | 32 | 147 | 47 | 100 | 26 | - | 30 |
| 27790-1212030X150 | A | stainless steel | - | 120 | M30 | 32 | 196 | 46 | 150 | 26 | - | 30 |
| 27790-1212030X200 | A | stainless steel | - | 120 | M30 | 32 | 246 | 46 | 200 | 26 | - | 30 |
| 27790-2106010X50 | B | steel | 45 | 60 | M10 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-2106010X100 | B | steel | 45 | 60 | M10 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-2106012X50 | B | steel | 45 | 60 | M12 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-2106012X100 | B | steel | 45 | 60 | M12 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-2106012X150 | B | steel | 45 | 60 | M12 | 22 | 182 | 32 | 150 | 14 | - | 7 |
| 27790-2108010X50 | B | steel | 54 | 80 | M10 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-2108010X100 | B | steel | 54 | 80 | M10 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-2108012X50 | B | steel | 54 | 80 | M12 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-2108012X100 | B | steel | 54 | 80 | M12 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-2108012X150 | B | steel | 54 | 80 | M12 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-2108014X50 | B | steel | 54 | 80 | M14 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-2108014X100 | B | steel | 54 | 80 | M14 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-2108014X150 | B | steel | 54 | 80 | M14 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-2108016X100 | B | steel | 54 | 80 | M16 | 25 | 135 | 35 | 100 | 16 | - | 10 |
| 27790-2108016X150 | B | steel | 54 | 80 | M16 | 25 | 185 | 35 | 150 | 16 | - | 10 |
| 27790-2108020X75 | B | steel | 54 | 80 | M20 | 25 | 111 | 36 | 75 | 20 | - | 10 |
| 27790-2108020X100 | B | steel | 54 | 80 | M20 | 25 | 136 | 36 | 100 | 20 | - | 10 |
| 27790-2108020X150 | B | steel | 54 | 80 | M20 | 25 | 186 | 36 | 150 | 20 | - | 10 |
| 27790-2108020X200 | B | steel | 54 | 80 | M20 | 25 | 236 | 36 | 200 | 20 | - | 10 |
| 27790-2110020X75 | B | steel | 69 | 100 | M20 | 28 | 113,5 | 38,5 | 75 | 20 | - | 15 |
| 27790-2110020X100 | B | steel | 69 | 100 | M20 | 28 | 138,5 | 38,5 | 100 | 20 | - | 15 |
| 27790-2110020X150 | B | steel | 69 | 100 | M20 | 28 | 188,5 | 38,5 | 150 | 20 | - | 15 |
| 27790-2110020X200 | B | steel | 69 | 100 | M20 | 28 | 238,5 | 38,5 | 200 | 20 | - | 15 |
| 27790-2110020X250 | B | steel | 69 | 100 | M20 | 28 | 288,5 | 38,5 | 250 | 20 | - | 15 |
| 27790-2110024X100 | B | steel | 69 | 100 | M24 | 28 | 138,5 | 38,5 | 100 | 24 | - | 15 |
| 27790-2110024X150 | B | steel | 69 | 100 | M24 | 28 | 188,5 | 38,5 | 150 | 24 | - | 15 |
| 27790-2110024X200 | B | steel | 69 | 100 | M24 | 28 | 238,5 | 38,5 | 200 | 24 | - | 15 |
| 27790-2110024X250 | B | steel | 69 | 100 | M24 | 28 | 288,5 | 38,5 | 250 | 24 | - | 15 |
| 27790-2206010X50 | B | stainless steel | 45 | 60 | M10 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-2206010X100 | B | stainless steel | 45 | 60 | M10 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-2206012X50 | B | stainless steel | 45 | 60 | M12 | 22 | 82 | 32 | 50 | 14 | - | 7 |
| 27790-2206012X100 | B | stainless steel | 45 | 60 | M12 | 22 | 132 | 32 | 100 | 14 | - | 7 |
| 27790-2206012X150 | B | stainless steel | 45 | 60 | M12 | 22 | 182 | 32 | 150 | 14 | - | 7 |
| 27790-2208010X50 | B | stainless steel | 54 | 80 | M10 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-2208010X75 | B | stainless steel | 54 | 80 | M10 | 25 | 110 | 35 | 75 | 14 | - | 10 |
| 27790-2208010X100 | B | stainless steel | 54 | 80 | M10 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-2208010X125 | B | stainless steel | 54 | 80 | M10 | 25 | 160 | 35 | 125 | 14 | - | 10 |
| 27790-2208012X50 | B | stainless steel | 54 | 80 | M12 | 25 | 85 | 35 | 50 | 14 | - | 10 |
| 27790-2208012X75 | B | stainless steel | 54 | 80 | M12 | 25 | 110 | 35 | 75 | 14 | - | 10 |
| 27790-2208012X100 | B | stainless steel | 54 | 80 | M12 | 25 | 135 | 35 | 100 | 14 | - | 10 |

Overview of items

| Order No. | Form | Main material | A | D | D1 | H | H1 | H2 | L | SW | SW1 | Load rating max. kN (static load only) |
|-------------------|------|-----------------|----|-----|-----|----|-------|------|-----|----|-----|--|
| 27790-2208012X125 | B | stainless steel | 54 | 80 | M12 | 25 | 160 | 35 | 125 | 14 | - | 10 |
| 27790-2208012X150 | B | stainless steel | 54 | 80 | M12 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-2208014X75 | B | stainless steel | 54 | 80 | M14 | 25 | 110 | 35 | 75 | 14 | - | 10 |
| 27790-2208014X100 | B | stainless steel | 54 | 80 | M14 | 25 | 135 | 35 | 100 | 14 | - | 10 |
| 27790-2208014X125 | B | stainless steel | 54 | 80 | M14 | 25 | 160 | 35 | 125 | 14 | - | 10 |
| 27790-2208014X150 | B | stainless steel | 54 | 80 | M14 | 25 | 185 | 35 | 150 | 14 | - | 10 |
| 27790-2208014X175 | B | stainless steel | 54 | 80 | M14 | 25 | 210 | 35 | 175 | 14 | - | 10 |
| 27790-2208016X75 | B | stainless steel | 54 | 80 | M16 | 25 | 110 | 35 | 75 | 13 | - | 10 |
| 27790-2208016X100 | B | stainless steel | 54 | 80 | M16 | 25 | 135 | 35 | 100 | 13 | - | 10 |
| 27790-2208016X125 | B | stainless steel | 54 | 80 | M16 | 25 | 160 | 35 | 125 | 13 | - | 10 |
| 27790-2208016X150 | B | stainless steel | 54 | 80 | M16 | 25 | 185 | 35 | 150 | 13 | - | 10 |
| 27790-2208016X175 | B | stainless steel | 54 | 80 | M16 | 25 | 210 | 35 | 175 | 13 | - | 10 |
| 27790-2208020X75 | B | stainless steel | 54 | 80 | M20 | 25 | 113 | 38 | 75 | 17 | - | 10 |
| 27790-2208020X100 | B | stainless steel | 54 | 80 | M20 | 25 | 138 | 38 | 100 | 17 | - | 10 |
| 27790-2208020X125 | B | stainless steel | 54 | 80 | M20 | 25 | 163 | 38 | 125 | 17 | - | 10 |
| 27790-2208020X150 | B | stainless steel | 54 | 80 | M20 | 25 | 188 | 38 | 150 | 17 | - | 10 |
| 27790-2208020X175 | B | stainless steel | 54 | 80 | M20 | 25 | 213 | 38 | 175 | 17 | - | 10 |
| 27790-2208020X200 | B | stainless steel | 54 | 80 | M20 | 25 | 238 | 38 | 200 | 17 | - | 10 |
| 27790-2208020X225 | B | stainless steel | 54 | 80 | M20 | 25 | 263 | 38 | 225 | 17 | - | 10 |
| 27790-2210020X75 | B | stainless steel | 69 | 100 | M20 | 30 | 118 | 43 | 75 | 17 | - | 15 |
| 27790-2210020X100 | B | stainless steel | 69 | 100 | M20 | 30 | 143 | 43 | 100 | 17 | - | 15 |
| 27790-2210020X125 | B | stainless steel | 69 | 100 | M20 | 30 | 168 | 43 | 125 | 17 | - | 15 |
| 27790-2210020X150 | B | stainless steel | 69 | 100 | M20 | 30 | 193 | 43 | 150 | 17 | - | 15 |
| 27790-2210020X175 | B | stainless steel | 69 | 100 | M20 | 30 | 218 | 43 | 175 | 17 | - | 15 |
| 27790-2210020X200 | B | stainless steel | 69 | 100 | M20 | 30 | 243 | 43 | 200 | 17 | - | 15 |
| 27790-2210024X100 | B | stainless steel | 69 | 100 | M24 | 30 | 144 | 44 | 100 | 20 | - | 15 |
| 27790-2210024X125 | B | stainless steel | 69 | 100 | M24 | 30 | 169 | 44 | 125 | 20 | - | 15 |
| 27790-2210024X150 | B | stainless steel | 69 | 100 | M24 | 30 | 194 | 44 | 150 | 20 | - | 15 |
| 27790-2210024X175 | B | stainless steel | 69 | 100 | M24 | 30 | 219 | 44 | 175 | 20 | - | 15 |
| 27790-2210024X200 | B | stainless steel | 69 | 100 | M24 | 30 | 244 | 44 | 200 | 20 | - | 15 |
| 27790-3105010X50 | C | steel | - | 50 | M10 | 19 | 79 | 29 | 50 | 14 | 5 | 4 |
| 27790-3105012X50 | C | steel | - | 50 | M12 | 19 | 79 | 29 | 50 | 14 | 6 | 4 |
| 27790-3105012X100 | C | steel | - | 50 | M12 | 19 | 129 | 29 | 100 | 14 | 6 | 4 |
| 27790-3105016X75 | C | steel | - | 50 | M16 | 19 | 104 | 29 | 75 | 16 | 8 | 4 |
| 27790-3105016X100 | C | steel | - | 50 | M16 | 19 | 129 | 29 | 100 | 16 | 8 | 4 |
| 27790-3105016X150 | C | steel | - | 50 | M16 | 19 | 179 | 29 | 150 | 16 | 8 | 4 |
| 27790-3106010X50 | C | steel | - | 60 | M10 | 22 | 82 | 32 | 50 | 14 | 5 | 7 |
| 27790-3106012X50 | C | steel | - | 60 | M12 | 22 | 82 | 32 | 50 | 14 | 6 | 7 |
| 27790-3106012X100 | C | steel | - | 60 | M12 | 22 | 132 | 32 | 100 | 14 | 6 | 7 |
| 27790-3106016X75 | C | steel | - | 60 | M16 | 22 | 108 | 33 | 75 | 16 | 8 | 7 |
| 27790-3106016X100 | C | steel | - | 60 | M16 | 22 | 133 | 33 | 100 | 16 | 8 | 7 |
| 27790-3106016X150 | C | steel | - | 60 | M16 | 22 | 183 | 33 | 150 | 16 | 8 | 7 |
| 27790-3108016X100 | C | steel | - | 80 | M16 | 25 | 135 | 35 | 100 | 16 | 8 | 10 |
| 27790-3108016X150 | C | steel | - | 80 | M16 | 25 | 185 | 35 | 150 | 16 | 8 | 10 |
| 27790-3108020X75 | C | steel | - | 80 | M20 | 25 | 111 | 36 | 75 | 20 | 10 | 10 |
| 27790-3110020X100 | C | steel | - | 100 | M20 | 28 | 138,5 | 38,5 | 100 | 20 | 10 | 15 |
| 27790-3110020X150 | C | steel | - | 100 | M20 | 28 | 188,5 | 38,5 | 150 | 20 | 10 | 15 |
| 27790-3110024X200 | C | steel | - | 100 | M24 | 28 | 238,5 | 38,5 | 200 | 24 | 10 | 15 |
| 27790-3112020X100 | C | steel | - | 120 | M20 | 32 | 142,5 | 42,5 | 100 | 20 | 10 | 30 |
| 27790-3112020X150 | C | steel | - | 120 | M20 | 32 | 192,5 | 42,5 | 150 | 20 | 10 | 30 |
| 27790-3112020X200 | C | steel | - | 120 | M20 | 32 | 242,5 | 42,5 | 200 | 20 | 10 | 30 |
| 27790-3112024X100 | C | steel | - | 120 | M24 | 32 | 142,5 | 42,5 | 100 | 24 | 10 | 30 |
| 27790-3112024X150 | C | steel | - | 120 | M24 | 32 | 192,5 | 42,5 | 150 | 24 | 10 | 30 |
| 27790-3112024X200 | C | steel | - | 120 | M24 | 32 | 242,5 | 42,5 | 200 | 24 | 10 | 30 |
| 27790-3112030X100 | C | steel | - | 120 | M30 | 32 | 143,5 | 43,5 | 100 | 30 | 10 | 30 |
| 27790-3112030X150 | C | steel | - | 120 | M30 | 32 | 193,5 | 43,5 | 150 | 30 | 10 | 30 |
| 27790-3112030X200 | C | steel | - | 120 | M30 | 32 | 243,5 | 43,5 | 200 | 30 | 10 | 30 |
| 27790-3205010X50 | C | stainless steel | - | 50 | M10 | 19 | 79 | 29 | 50 | 14 | 5 | 4 |
| 27790-3205012X50 | C | stainless steel | - | 50 | M12 | 19 | 79 | 29 | 50 | 14 | 6 | 4 |
| 27790-3205012X100 | C | stainless steel | - | 50 | M12 | 19 | 129 | 29 | 100 | 14 | 6 | 4 |
| 27790-3205016X75 | C | stainless steel | - | 50 | M16 | 19 | 104 | 29 | 75 | 13 | 8 | 4 |
| 27790-3205016X100 | C | stainless steel | - | 50 | M16 | 19 | 129 | 29 | 100 | 13 | 8 | 4 |
| 27790-3205016X150 | C | stainless steel | - | 50 | M16 | 19 | 179 | 29 | 150 | 13 | 8 | 4 |
| 27790-3205016X200 | C | stainless steel | - | 50 | M16 | 19 | 229 | 29 | 200 | 13 | 8 | 4 |

Overview of items

| Order No. | Form | Main material | A | D | D1 | H | H1 | H2 | L | SW | SW1 | Load rating max. kN (static load only) |
|-------------------|------|-----------------|----|-----|-----|----|-----|----|-----|----|-----|--|
| 27790-3206010X50 | C | stainless steel | - | 60 | M10 | 22 | 82 | 32 | 50 | 14 | 5 | 7 |
| 27790-3206012X50 | C | stainless steel | - | 60 | M12 | 22 | 82 | 32 | 50 | 14 | 6 | 7 |
| 27790-3206012X100 | C | stainless steel | - | 60 | M12 | 22 | 132 | 32 | 100 | 14 | 6 | 7 |
| 27790-3206016X75 | C | stainless steel | - | 60 | M16 | 22 | 108 | 33 | 75 | 13 | 8 | 7 |
| 27790-3206016X100 | C | stainless steel | - | 60 | M16 | 22 | 133 | 33 | 100 | 13 | 8 | 7 |
| 27790-3206016X150 | C | stainless steel | - | 60 | M16 | 22 | 183 | 33 | 150 | 13 | 8 | 7 |
| 27790-3206016X200 | C | stainless steel | - | 60 | M16 | 22 | 233 | 33 | 200 | 13 | 8 | 7 |
| 27790-3208016X75 | C | stainless steel | - | 80 | M16 | 25 | 110 | 35 | 75 | 13 | 8 | 10 |
| 27790-3208016X100 | C | stainless steel | - | 80 | M16 | 25 | 135 | 35 | 100 | 13 | 8 | 10 |
| 27790-3208016X125 | C | stainless steel | - | 80 | M16 | 25 | 160 | 35 | 125 | 13 | 8 | 10 |
| 27790-3208016X150 | C | stainless steel | - | 80 | M16 | 25 | 185 | 35 | 150 | 13 | 8 | 10 |
| 27790-3208016X175 | C | stainless steel | - | 80 | M16 | 25 | 210 | 35 | 175 | 13 | 8 | 10 |
| 27790-3208020X75 | C | stainless steel | - | 80 | M20 | 25 | 113 | 38 | 75 | 17 | 10 | 10 |
| 27790-3208020X200 | C | stainless steel | - | 80 | M20 | 25 | 238 | 38 | 200 | 17 | 10 | 10 |
| 27790-3210020X150 | C | stainless steel | - | 100 | M20 | 30 | 193 | 43 | 150 | 17 | 10 | 15 |
| 27790-3212020X100 | C | stainless steel | - | 120 | M20 | 32 | 143 | 43 | 100 | 17 | 10 | 30 |
| 27790-3212020X150 | C | stainless steel | - | 120 | M20 | 32 | 194 | 44 | 150 | 17 | 10 | 30 |
| 27790-3212020X200 | C | stainless steel | - | 120 | M20 | 32 | 244 | 44 | 200 | 17 | 10 | 30 |
| 27790-3212024X100 | C | stainless steel | - | 120 | M24 | 32 | 145 | 45 | 100 | 20 | 10 | 30 |
| 27790-3212024X150 | C | stainless steel | - | 120 | M24 | 32 | 195 | 45 | 150 | 20 | 10 | 30 |
| 27790-3212024X200 | C | stainless steel | - | 120 | M24 | 32 | 245 | 45 | 200 | 20 | 10 | 30 |
| 27790-3212030X100 | C | stainless steel | - | 120 | M30 | 32 | 147 | 47 | 100 | 26 | 10 | 30 |
| 27790-3212030X150 | C | stainless steel | - | 120 | M30 | 32 | 197 | 47 | 150 | 26 | 10 | 30 |
| 27790-3212030X200 | C | stainless steel | - | 120 | M30 | 32 | 247 | 47 | 200 | 26 | 10 | 30 |
| 27790-4106010X50 | D | steel | 45 | 60 | M10 | 22 | 82 | 32 | 50 | 14 | 5 | 7 |
| 27790-4106012X50 | D | steel | 45 | 60 | M12 | 22 | 82 | 32 | 50 | 14 | 6 | 7 |
| 27790-4106012X100 | D | steel | 45 | 60 | M12 | 22 | 132 | 32 | 100 | 14 | 6 | 7 |
| 27790-4106016X75 | D | steel | 45 | 60 | M16 | 22 | 108 | 33 | 75 | 16 | 8 | 7 |
| 27790-4106016X100 | D | steel | 45 | 60 | M16 | 22 | 133 | 33 | 100 | 16 | 8 | 7 |
| 27790-4106016X150 | D | steel | 45 | 60 | M16 | 22 | 183 | 33 | 150 | 16 | 8 | 7 |
| 27790-4106016X200 | D | steel | 45 | 60 | M16 | 22 | 233 | 33 | 200 | 16 | 8 | 7 |
| 27790-4206010X50 | D | stainless steel | 45 | 60 | M10 | 22 | 82 | 32 | 50 | 14 | 5 | 7 |
| 27790-4206012X50 | D | stainless steel | 45 | 60 | M12 | 22 | 82 | 32 | 50 | 14 | 6 | 7 |
| 27790-4206012X100 | D | stainless steel | 45 | 60 | M12 | 22 | 132 | 32 | 100 | 14 | 6 | 7 |
| 27790-4206016X75 | D | stainless steel | 45 | 60 | M16 | 22 | 108 | 33 | 75 | 13 | 8 | 7 |
| 27790-4206016X100 | D | stainless steel | 45 | 60 | M16 | 22 | 133 | 33 | 100 | 13 | 8 | 7 |
| 27790-4206016X150 | D | stainless steel | 45 | 60 | M16 | 22 | 183 | 33 | 150 | 13 | 8 | 7 |
| 27790-4206016X200 | D | stainless steel | 45 | 60 | M16 | 22 | 233 | 33 | 200 | 13 | 8 | 7 |