


Item description/product images

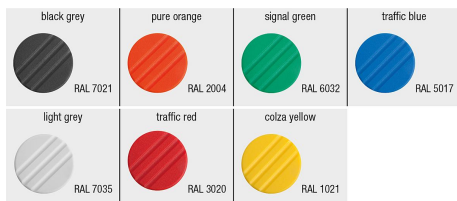


Description

**Material:**  
Black thermoplastic.  
Bush grade 5.8 steel.

**Version:**  
Steel trivalent blue-passivated.

**Note:**  
Form H: without locking grub screw  
Form M: with locking grub screw

Drawings

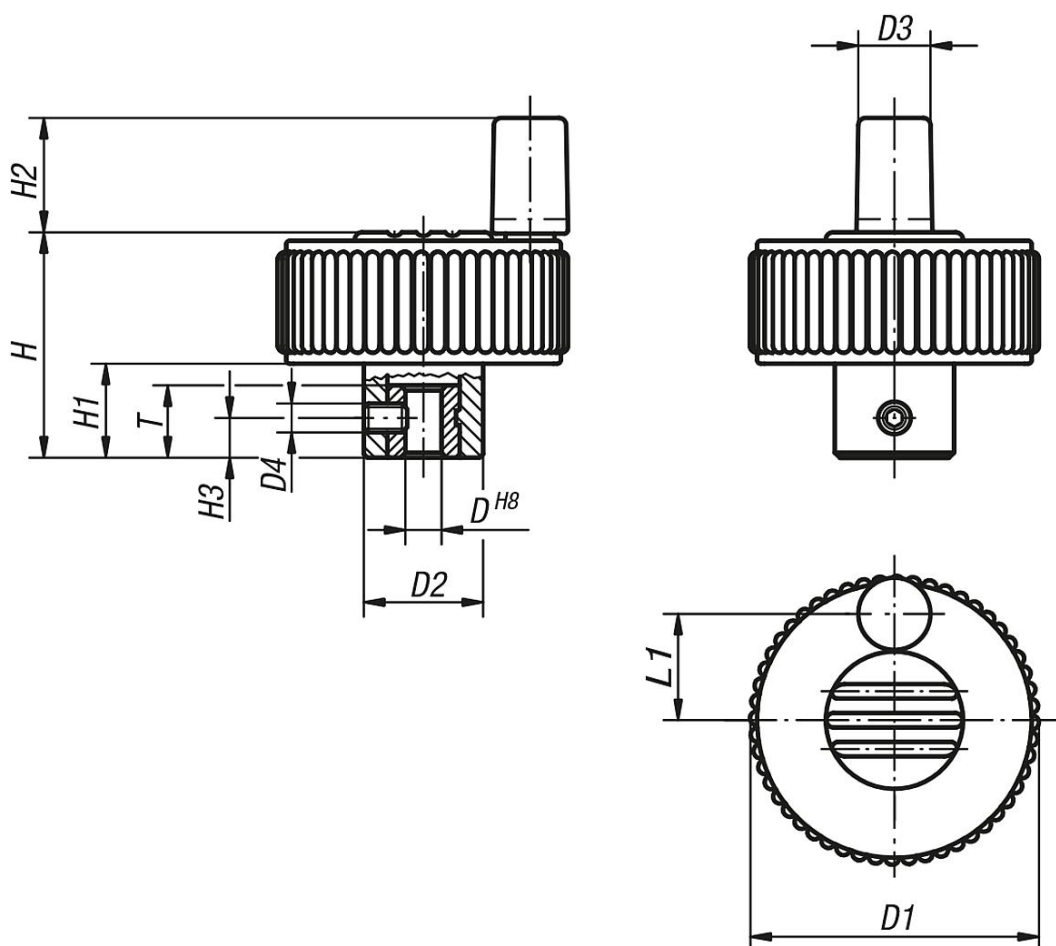

Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	L1	T
06268-2106	H	black grey RAL 7021	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21061	H	orange RAL 2004	6H8	40	16,5	10	-	31	13	16	-	15	10

## Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	H3	L1	T
06268-21062	H	signal green RAL6032	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21063	H	blue RAL5017	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21065	H	light grey RAL 7035	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21066	H	traffic red RAL 3020	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-21067	H	colza yellow RAL 1021	6H8	40	16,5	10	-	31	13	16	-	15	10
06268-2206	H	black grey RAL 7021	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22061	H	orange RAL 2004	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22062	H	signal green RAL6032	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22063	H	blue RAL5017	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22065	H	light grey RAL 7035	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22066	H	traffic red RAL 3020	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-22067	H	colza yellow RAL 1021	6H8	50	18	10	-	36	15	16	-	18,5	10
06268-2308	H	black grey RAL 7021	8H8	63	22	10	-	41	17	16	-	25	14
06268-23081	H	orange RAL 2004	8H8	63	22	10	-	41	17	16	-	25	14
06268-23082	H	signal green RAL6032	8H8	63	22	10	-	41	17	16	-	25	14
06268-23083	H	blue RAL5017	8H8	63	22	10	-	41	17	16	-	25	14
06268-23085	H	light grey RAL 7035	8H8	63	22	10	-	41	17	16	-	25	14
06268-23086	H	traffic red RAL 3020	8H8	63	22	10	-	41	17	16	-	25	14
06268-23087	H	colza yellow RAL 1021	8H8	63	22	10	-	41	17	16	-	25	14
06268-1106	M	black grey RAL 7021	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11061	M	orange RAL 2004	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11062	M	signal green RAL6032	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11063	M	blue RAL5017	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11065	M	light grey RAL 7035	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11066	M	traffic red RAL 3020	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-11067	M	colza yellow RAL 1021	6H8	40	16,5	10	M4	31	13	16	5,5	15	10
06268-1206	M	black grey RAL 7021	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12061	M	orange RAL 2004	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12062	M	signal green RAL6032	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12063	M	blue RAL5017	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12065	M	light grey RAL 7035	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12066	M	traffic red RAL 3020	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-12067	M	colza yellow RAL 1021	6H8	50	18	10	M4	36	15	16	5,5	18,5	10
06268-1308	M	black grey RAL 7021	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13081	M	orange RAL 2004	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13082	M	signal green RAL6032	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13083	M	blue RAL5017	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13085	M	light grey RAL 7035	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13086	M	traffic red RAL 3020	8H8	63	22	10	M4	41	17	16	8	25	14
06268-13087	M	colza yellow RAL 1021	8H8	63	22	10	M4	41	17	16	8	25	14