


Item description/product images

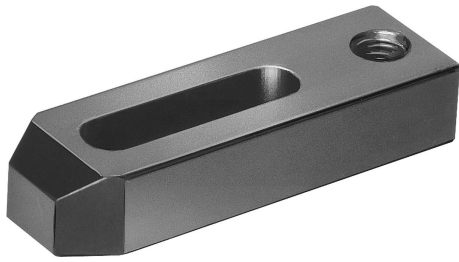


Description

Material:
Carbon steel.

Version:
Tempered and black oxidised.

Drawings

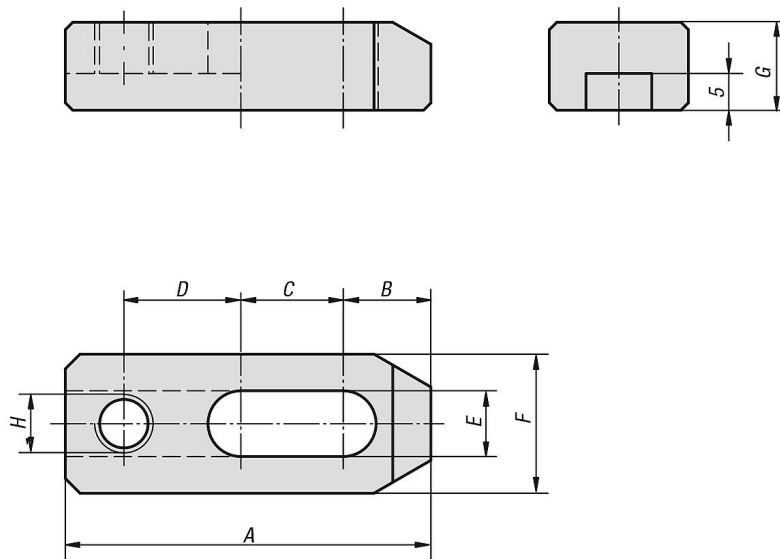

Overview of items

Order No.	A	B	C	D	E	F	G	H
04055-08040	40	10	6	16	9	19	12	M8
04055-08050	50	12	14	16	9	19	12	M8
04055-08063	63	12	27	16	9	19	12	M8
04055-10050	50	12	8	20	11	25	12	M10
04055-10063	63	15	18	20	11	25	12	M10
04055-10080	80	15	32	23	11	25	16	M10
04055-10100	100	15	40	35	11	25	16	M10
04055-10125	125	15	50	50	11	25	16	M10
04055-12063	63	14	14	24	13	32	16	M12
04055-12080	80	20	25	24	13	32	16	M12
04055-12100	100	20	40	29	13	32	19	M12
04055-12125	125	20	50	44	13	32	19	M12
04055-12160	160	20	60	69	13	32	19	M12
04055-16080	80	18	17	30	17	38	19	M16
04055-16100	100	25	30	30	17	38	25	M16
04055-16125	125	25	45	40	17	38	25	M16
04055-16160	160	25	65	55	17	38	25	M16
04055-20160	160	32	60	52	21	50	25	M20
04055-20200	200	32	80	72	21	50	25	M20

